


On-Demand Rotary Gasket Cutting

Clean Cuts. Correct Fit.
 Anywhere.



When a Gasket Fails

Production can stop instantly. Waiting on replacements costs time and money. With ALLPAX, cut a precise gasket on the spot and restore service fast.

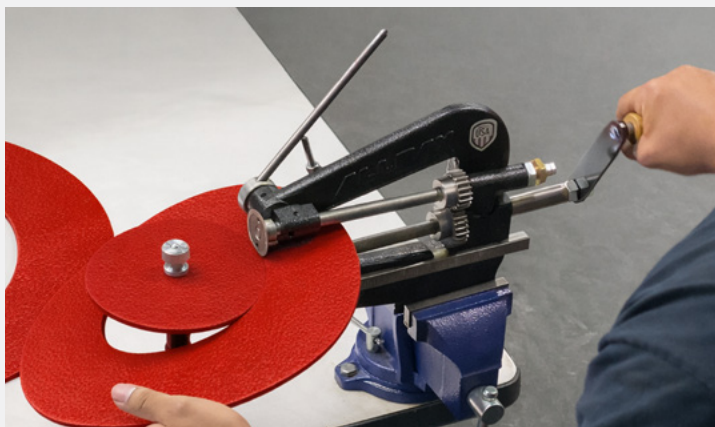

ALLPAX Rotary-Style Gasket Cutters

- Mounts easily to vise or angle iron
- Rotary-style cutting for smooth, controlled operation
- Stainless steel components and cast iron frame
- Durable construction for repeated use
- Easy material setup and alignment
- Compatible with optional scale bar extensions

Cuts	Range	Materials
Circular flanges and rings up to 1/4" (6.4mm) thick material	Standard: 2" I.D. to 22" O.D. Metric: 51 mm I.D. to 56 cm O.D. (Expandable with accessory scale bars)	Rubber, Cork, Fiber, and other non-metallics



ALLPAX®

Standard Rotary-Style Gasket Cutter



PART No. AX7000


Metric Rotary-Style Gasket Cutter



PART No. AX7050

ALL ROTARY-STYLE CUTTERS INCLUDE:


Heat-Treated Steel
Rotary Cutting Discs

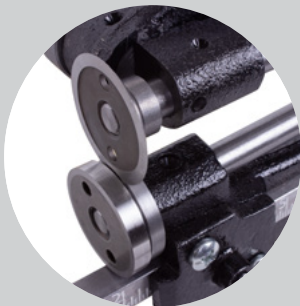

Hole Punch &
Spanner Wrench



One Extension Bar
(Standard or Metric)

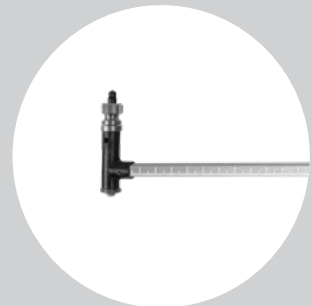

SCAN THE QR CODE

To view our complete line of
gasket fabrication tools

