

DASHIELL

490-48-VPB

The modern mobile-inspired Dashiell chandelier is designed to spark conversations. While constructed of substantial materials, this chandelier maintains a light, balanced appearance with an innate sense of movement. Slender Vintage Polished Brass arms are capped with tapered cylindrical alabaster shades, adding a note of contrast to the upscale fixture. The distinctive fluted holders of the shades provide additional style. Illuminated by LED, Dashiell is available in two sizes.

*Due to the one-of-a-kind nature of the medium, exact colors and patterns may vary slightly from the image shown.

FINISHES

VINTAGE POLISHED BRASS

Coastal Suitable Finish (EPM): No

DIMENSIONS

Height: 13"
Width/Diameter: 48"
Minimum Height: 18.5"
Maximum Height: 87"
Canopy/Backplate: 6"
Hanging Type: 72" Chain
Product Weight: 26.79lb
Canopy/Backplate Shape: Round
Sloped Ceiling Compatible: No
Living Finish: No
Uplight Only: No

Shade

Shade 1: Natural Stone
Shade 1 Finish: Alabaster
Shade 1 Top Width: 1.75"
Shade 1 Bottom L/W: 0" / 2.5"
Shade 1 Height: 8.25"

ELECTRICAL




Bulb 1

Bulb Included: N/A
Socket: Integrated LED
Max Wattage: 28
Bulb Quantity: 6
Bulb Included: Yes
Wire Length: 120"
Cord Type: SPT-1 SILVER W/ TINNED GROUND WIRE
Dimmer Type: ELV, TRIAC, 0-10 VOLT
Gem Box Required (2"x3"): No
Dark Sky: No
CRI: 90
Color Temp.: 2700k
Lumens: 1875
Title 24: No
Field Serviceable: No

SHIPPING

Carton 1: 34" x 24" x 7"
Carton 1 Weight: 32lb
Shipping Method: Ground
Country of Origin: VN

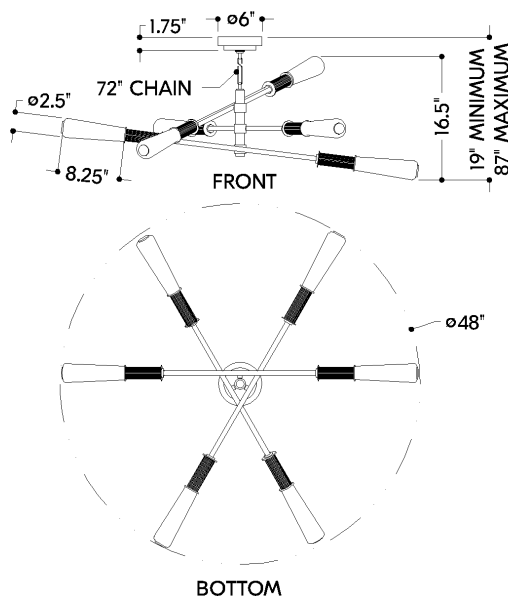

HUDSON VALLEY
LIGHTING GROUP

| hvlgroup.com | 1.800.814.3993

REVISED 3.11.2022