

16 AWG

GC002



QUICKLY CONNECT. M6 EYELET CONNECTORS.

DESIGNED FOR
NOCO genius
BATTERY CHARGERS AND MAINTAINERS.

COMPATIBLE WITH ALL NEW GENIUS:

GENIUS1

GENIUS2

GENIUS5

GENIUS10

GENIUS2X2

GENIUS2X4

+ PREVIOUS NOCO G SERIES:


G750

G7200

G1100

G4

G3500

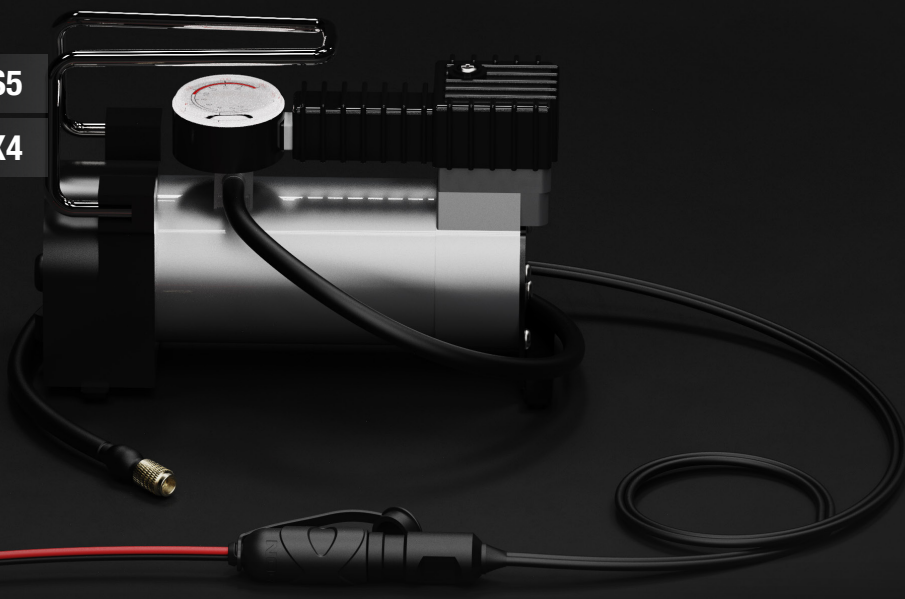

NOCO

30339 Diamond Parkway, #102
Glenwillow, OH 44139 | USA
1.800.456.6626

no.co

MADE FOR GENIUS.

IMPROVED EYELET DESIGN.

The GC002 M6 Eyelet Connectors are compatible with the X-Connect on Genius Chargers. Permanently mount eyelets on battery terminals to create a convenient connection to quickly plug in your NOCO Genius battery charger for daily charging and battery maintenance.

HARD MOUNT. PERMANENT CONNECTION.

Leave GC002 hard-mounted to battery terminals and easily move Genius chargers between batteries.

INTEGRATED FUSE.

Built-in 20A fuse protection for increased safety. The 20A fuse provides equal protection while being 45% smaller than the previous NOCO 10A Fuse.


SUPERIOR CONDUCTIVITY.

New copper-plated eyelets improve charging performance.

16 AWG WIRE.

6mm Diameter

WHAT'S IN THE BOX

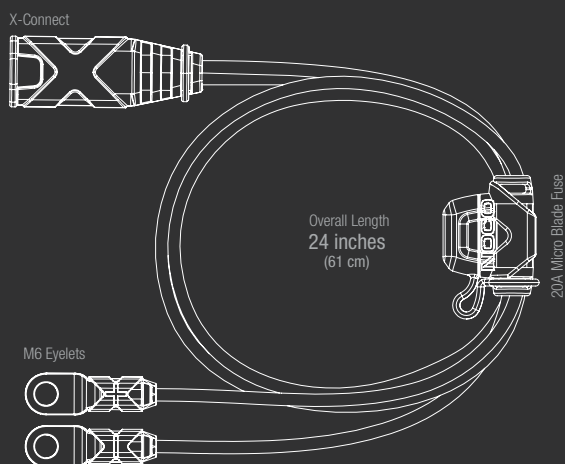

TECHNICAL SPECIFICATIONS

WIRE SIZE:	16 AWG	
INPUT:	X-Connect Female	
FUSE:	20 Amp Micro Blade	
CABLE LENGTH:	18.5 in (47cm)	
WEIGHT:	0.18 lbs (0.08kg)	
VOLUMETRICS:	Retail Packaging: Dimensions: 3.2" x 1.6" x 5.1" Weight: 0.20 lbs UPC: 0-46221-10055-6	Master Carton: Dimensions: 6.1" x 5.7" x 7.7" Weight: 1.68 lbs Quantity: 6 UCC: 20046221100550
	Inner Carton: Dimensions: 5.4" x 1.9" x 3.7" Weight: 0.22 lbs	Units Per Pallet: 1,260 Units

NOCO

30339 Diamond Parkway, #102
Glenwillow, OH 44139 | USA
1.800.456.6626

no.co