

SORRENTO

474-22-VB/VPT

A celebration of the beauty of natural alabaster, this minimalist tube sconce is a timeless staple for the modern home. An elongated backplate frames the alabaster shade with a slim touch of metal. The Vintage and Patina Brass finishes forge a geometric relationship with the softness of the natural veining of the stone. Available in two sizes, Sorrento has bath and powder room crossover appeal.

*Due to the one-of-a-kind nature of the medium, exact colors and patterns may vary slightly from the image shown.

FINISHES

VINTAGE BRASS w/ VINTAGE PEWTER

Coastal Suitable Finish (EPM): No

DIMENSIONS

Height: 22"

Width/Diameter: 3"

Canopy/Backplate: 3"

Product Weight: 10.6lb

Extension: 3.75"

Top to Center: 11"

Canopy/Backplate Shape: Rectangle

Sloped Ceiling Compatible: No

Living Finish: Yes

Uplight Only: No

Shade

Shade 1: Natural Stone

Shade 1 Finish: Alabaster

Shade 1 Top Width: 2.75"

Shade 1 Height: 19.25"

ELECTRICAL



Bulb 1

Bulb Included: N/A

Socket: Integrated LED

Bulb Type: LED

Max Wattage: 12

Bulb Quantity: 1

Bulb Included: Yes

Wire Length: 7"

Cord Type: B & W TEFLON W/ GROUND WIRE

Dimmer Type: ELV, TRIAC

Gem Box Required (2"x3"): Yes

Dark Sky: No

CRI: 90

Color Temp.: 2700k

Lumens: 425

Title 24: No

Field Serviceable: No



SHIPPING

Carton 1: 26" x 8" x 7"

Carton 1 Weight: 12lb

Shipping Method: Ground

Country of Origin: VN

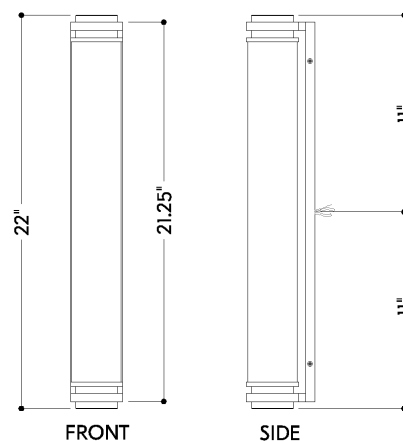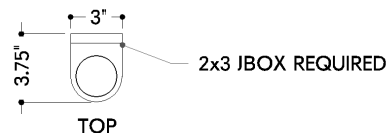

HUDSON VALLEY
LIGHTING GROUP

| hvlgroup.com | 1.800.814.3993

REVISED 3.11.2022