

Types A, ABB, BB and BBL Insulating Bushings

For Threaded Rigid Conduit and IMC.

NEC/CEC:
Listed for Ordinary Locations

NEC/CEC:
Listed for Ordinary Locations


Type A

Applications

- To insulate end of threaded rigid and IMC.

NEC/CEC Certifications and Compliances

- UL Listed: E-11853
- CSA Certified: 065183

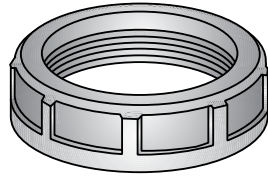

Type A

Dimensions in Millimeters (Inches)			
Trade Size (Inches)	Outside Dia.	Overall Height	Catalog Number
1/2	28.70 (1.13)	12.70 (0.50)	A-50
3/4	35.05 (1.38)	12.70 (0.50)	A-75
1	44.45 (1.75)	16.00 (0.63)	A-100
1-1/4	54.10 (2.13)	19.05 (0.75)	A-125
1-1/2	60.45 (2.38)	19.05 (0.75)	A-150
2	73.15 (2.88)	19.05 (0.75)	A-200
2-1/2	85.85 (3.38)	22.35 (0.88)	A-250
3	101.60 (4.00)	22.35 (0.88)	A-300
3-1/2	117.60 (4.63)	22.35 (0.88)	A-350
4	130.30 (5.13)	22.35 (0.88)	A-400
5	158.75 (6.25)	28.70 (1.13)	A-500
6	187.45 (7.38)	28.70 (1.13)	A-600


Type BB

Applications

- To insulate cables passing through metal boxes or troughs.

NEC/CEC Certifications and Compliances

- UL Listed: E-20933
- CSA Certified: 11584

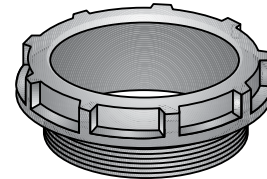

Type BB

Dimensions in Millimeters (Inches)				
Trade Size (Inches)	Outside Dia.	Bushing Hole Dia.	Thread Length	Catalog Number
1/2	28.70 (1.13)	16.00 (0.63)	9.65 (0.38)	BB-50
3/4	35.05 (1.38)	19.05 (0.75)	9.65 (0.38)	BB-75
1	44.45 (1.75)	25.40 (1.00)	12.70 (0.50)	BB-100
1-1/4	54.10 (2.13)	31.75 (1.25)	12.70 (0.50)	BB-125
1-1/2	60.45 (2.38)	38.10 (1.50)	12.70 (0.50)	BB-150
2	73.15 (2.88)	50.80 (2.00)	12.70 (0.50)	BB-200
2-1/2	85.85 (3.38)	60.45 (2.38)	16.00 (0.63)	BB-250
3	101.60 (4.00)	76.20 (3.00)	16.00 (0.63)	BB-300
3-1/2	117.60 (4.63)	88.90 (3.50)	16.00 (0.63)	BB-350
4	130.30 (5.13)	98.55 (3.88)	16.00 (0.63)	BB-400
5	158.75 (6.25)	123.95 (4.88)	19.05 (0.75)	BB-500
6	187.45 (7.38)	149.35 (5.88)	19.05 (0.75)	BB-600