


JOB NAME:DATE:TYPE:

COMMENTS:

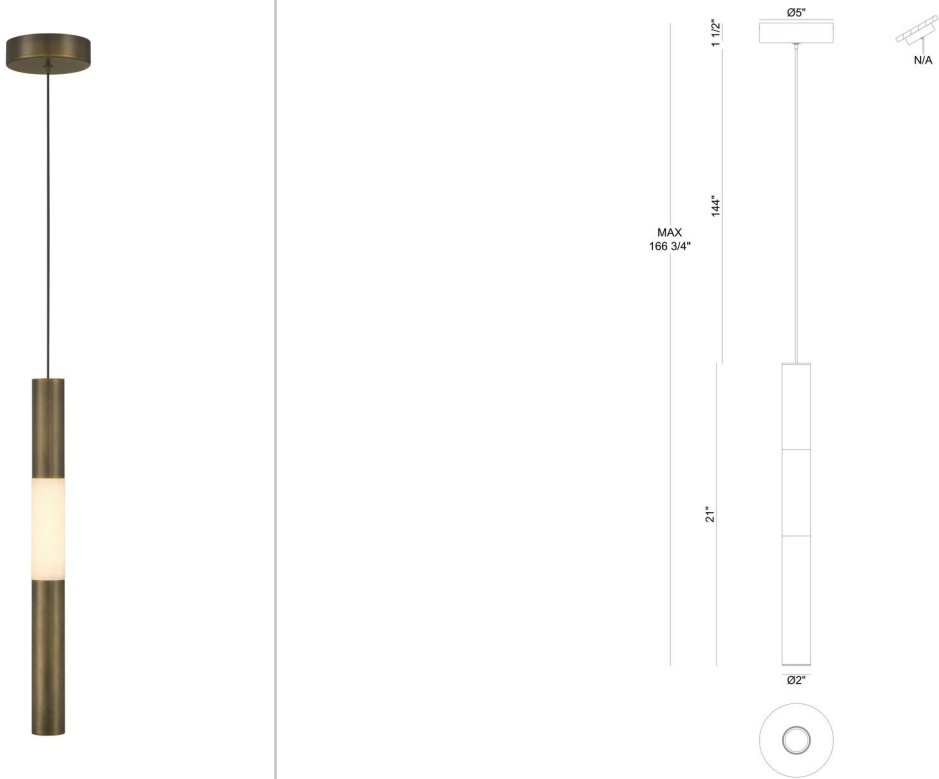

LIGHT INFORMATION

Light Type	Integrated LED
CRI	90
Delivered Lumens	1205
Color Temperature	3000K
LED Lifespan (L70)	50000
Light Direction	Ambient
Dimming Method	Triac/Elv
Current Type	DC
Input Voltage	120-277
Total Wattage	20

DIMENSIONS & WEIGHT

Height (In)	21
Min Height (In)	32.38
Max Height (In)	166.75
Diameter (In)	2
Weight (Lbs)	4.66

INSTALLATION

Mounting Type	J-Box
Rating	Dry
Hanging Support Type	Aircraft Cable

PRODUCT FINISH

Weathered Brass

SHADE FINISH

Cylindrical Alabaster

ADDITIONAL INFORMATION

Power Wire Length (In)	144
Replaceable LED	Yes

PRODUCT FEATURES

This product is crafted from natural stone; inherent variations in color, pattern, and texture are to be expected.

CERTIFICATIONS & COMPLIANCE

