


# ASSEMBLY AND INSTALLATION INSTRUCTIONS

H0266

**WARNING:** TO AVOID RISK OF ELECTRICAL SHOCK, BE SURE TO SHUT OFF POWER BEFORE INSTALLING OR SERVICING THIS FIXTURE.

**NOTES:** 1. Before installing, consult local electrical codes for wiring and grounding requirements.  
2. READ AND SAVE THESE INSTRUCTIONS.

## Hardware Package (included):

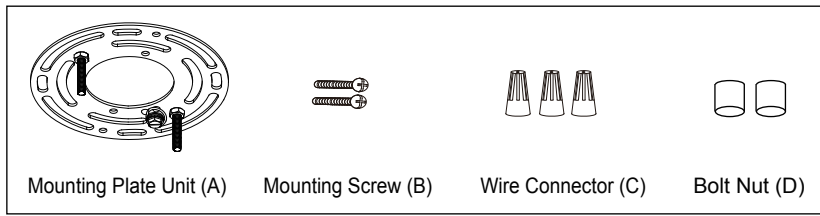


## Installation Steps

Turn off the power at fuse or circuit box

1. Attach the mounting plate unit (A) to the outlet box by using two mounting screws (B).
2. Attach the threaded pipe to the coupling of the main fixture, secure it with a washer and hex nut. Adjust the length of the threaded pipe if necessary.
3. Attach the tube, metal pad and cap onto the coupling by inserting the threaded pipe, and then secure with the metal part.
4. Adjust the arms of the fixture to fit in six slots of decorative cup, then put the decorative cup on the fixture by inserting the threaded pipe-1, secure it with the finial.
5. Rod Connections:
  - a. Thread the fixture wire from the fixture through the lower rod, then secure the lower rod onto fixture using the threaded pipe.
  - b. Thread the fixture wire through the middle rod and then secure the middle rod onto the lower rod using the threaded pipe.
  - c. Thread the fixture wire through the upper rod, then secure the upper rod onto the middle rod using the threaded pipe.

**Note: Length adjustable from 21-3/4" to 72-3/4". Use fewer rods if shorter length is desired.**
6. Thread the fixture wire through the canopy kit, then secure the rod assembly to the set threaded pipe of the canopy kit.

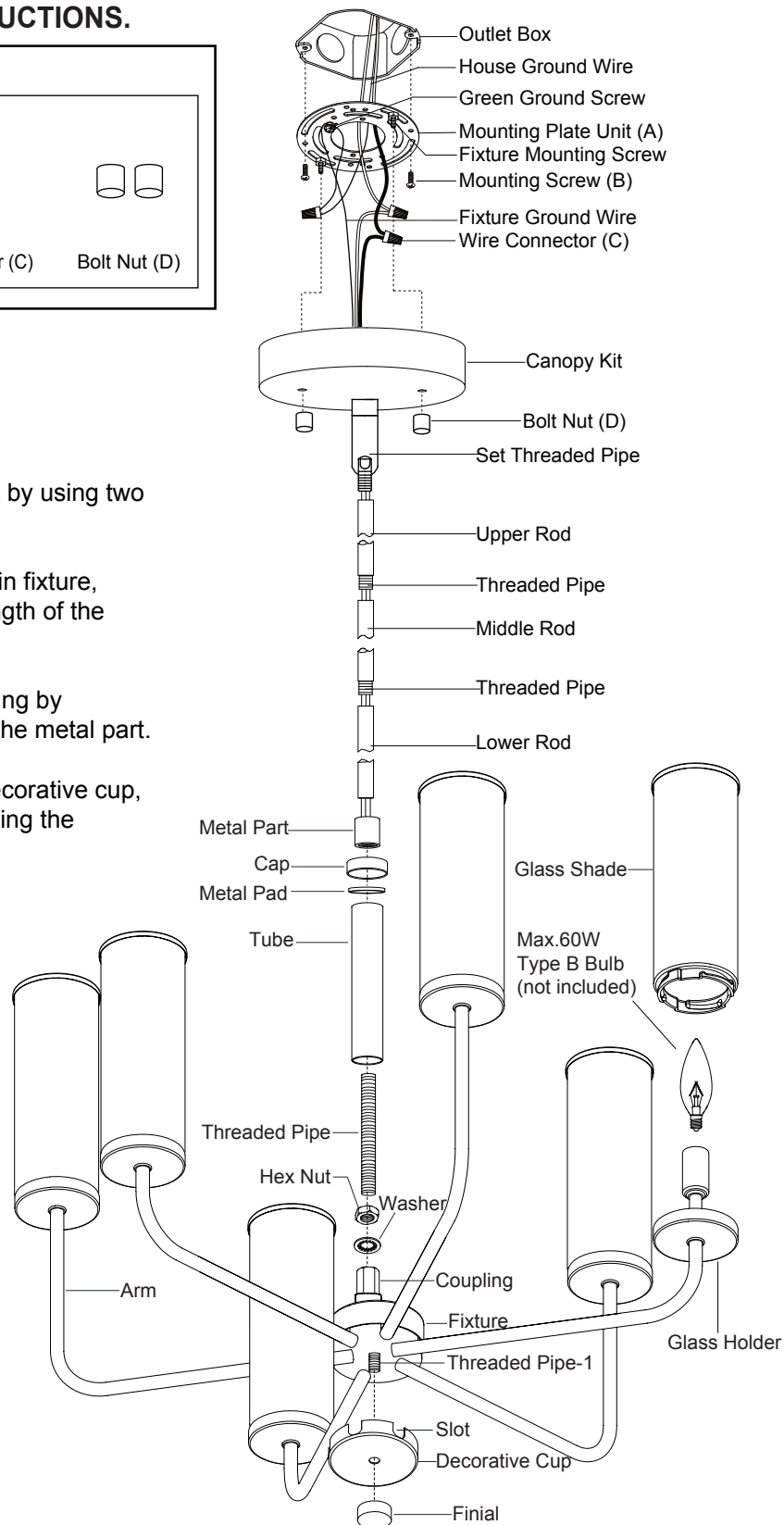

**VAXCEL**

220228


7. Pull out the source wires from the outlet box. Make wire connections using wire connectors (C) as follows:
  - Connect the smooth-coated wire (marked) from the fixture to the black wire from the power source.
  - Connect the ribbed-coated wire (unmarked) from the fixture to the white wire from the power source.
  - Attach the fixture ground wire to the mounting plate unit (A) with the green ground screw, then connect it to the house ground wire with a wire connector (C).
 Carefully put the wires back into the outlet box.

8. Attach the canopy to the mounting plate unit (A), and then secure it with two bolt nuts (D).

9. Install 6 x 60W max. candelabra base bulb (not included). See relamping label at socket area or packaging for maximum wattage allowed.



10. Rotate the glass shades to the glass holder tightly.

11. Angled mounting recommended for a vaulted or angled ceiling. (See Fig.1)

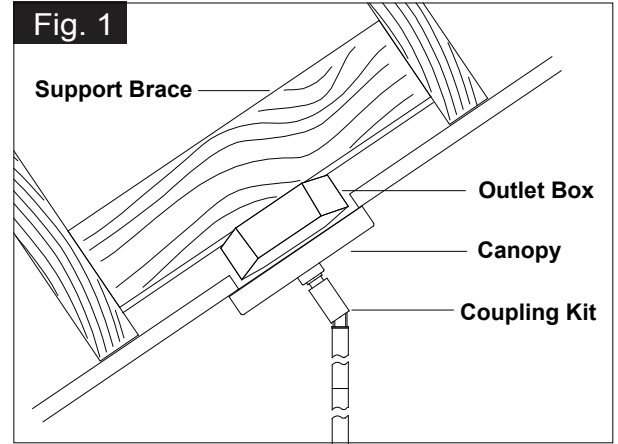

**Turn on the power at fuse or circuit box**

The following parts are available for re-order if damaged or missing.

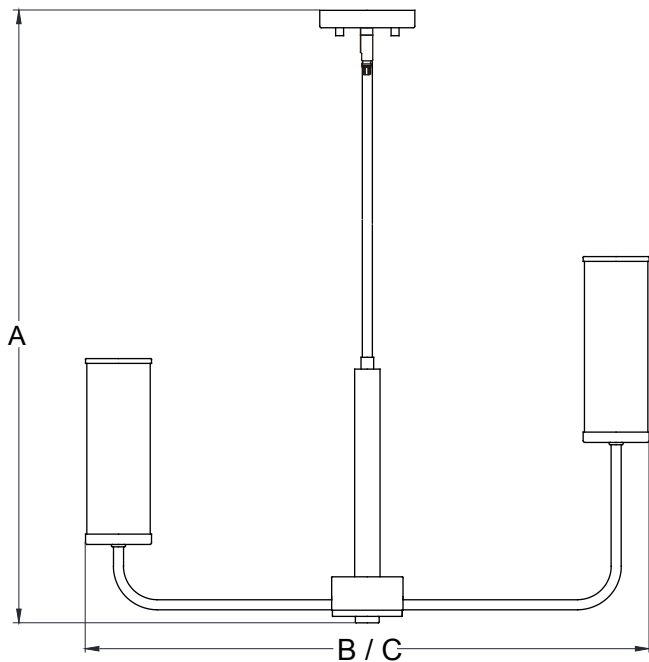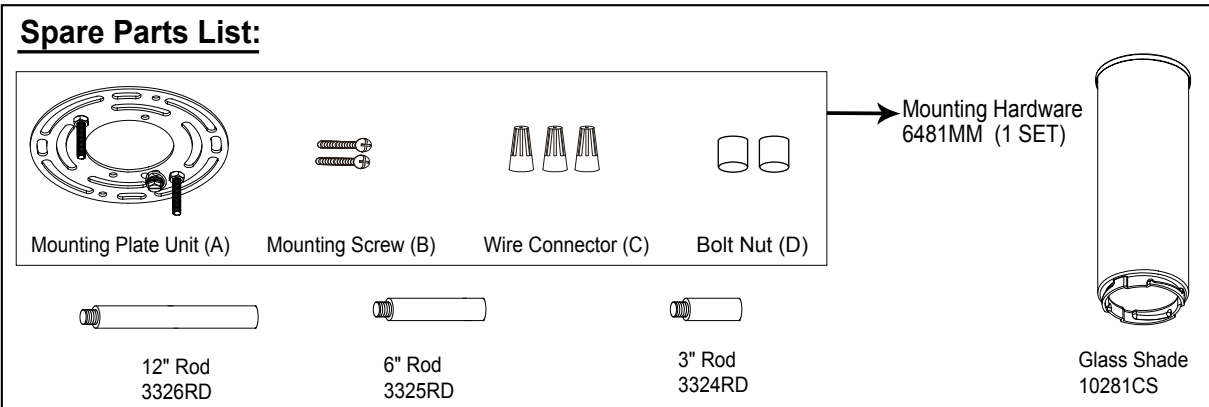

**A: 21-3/4"~72-3/4"**

**B: 28"**

**C: 28"**