

10A | 60PSI

NOCO® AIR10



## ULTRAFAST® PORTABLE AIR COMPRESSOR.

### UNPARALLELED SPEED.

NOCO AIR has been tested and proven to operate longer and inflate faster than leading competitors. Inflate flat tires from 0 to 40 psi in under 4 minutes.

### COMPACT DESIGN.

Integrated hose clips, dedicated slots for accessories, and effortless power-cord storage allow AIR to be quickly and easily stored or used.

### PREMIUM BUILD.

NOCO AIR is built with solid aluminum, heavy-duty powder coat, and reinforced plastic.

### LED FLASHLIGHT.

Provides a tactical-grade experience with long-range, bright illumination, controllable luminosity, and emergency modes.



NOCO®

30339 Diamond Parkway, #102  
Glenwillow, OH 44139 | USA  
1.800.456.6626

no.co

# ULTRAFAST<sup>®</sup> INFLATION



# SMART PRESSURE AUTO-SHUTOFF

AIR automatically shuts off upon reaching the desired pressure. Utilizing a unique algorithm — AIR achieves precise accuracy even at higher pressure.



Adapters

Integrated Hose Clip

**138 W**  
MOTOR POWER



**3.8 MIN** 0-40 PSI  
TIME TO INFLATE \*205-65R16 95H TIRE

**36 SLPM**  
FLOW RATE

## INTUITIVE INTERFACE.



## WHAT'S IN THE BOX

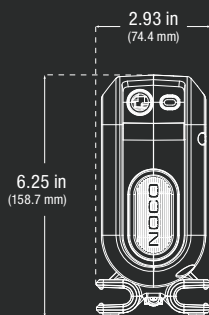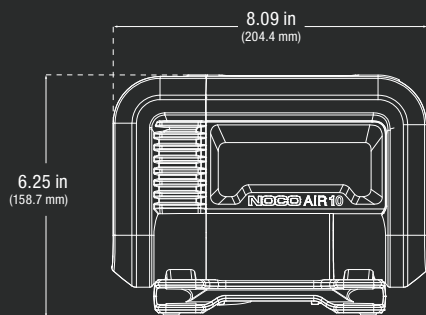

AIR10 Portable Air Compressor w/  
3ft Braided Hose & 10ft Power Cord  
+ 12V Cigarette Lighter Plug



User Guide &  
Warranty Information

- Needle Adapter
- Presta Valve Adapter
- Inflatable Toy Adapter



Microfiber Storage Bag

## TOTAL VERSATILITY.

With its rugged portable design, integrated cord management, dedicated slots for accessories, and ultra-compact size, it can easily be stored - and ready to take on anything.

## TECHNICAL SPECIFICATIONS

|                                                 |                                                                                                                             |
|-------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------|
| MAX AIRFLOW AT 0 PSI:                           | 36 SLPM                                                                                                                     |
| MAX PRESSURE:                                   | 60 psi / 4.14 bar / 413.68 kPa                                                                                              |
| MOTOR RATING:                                   | 138W                                                                                                                        |
| MOTOR MAX CURRENT DRAW:                         | 12A                                                                                                                         |
| DUTY CYCLE:                                     | 25 min @ 30PSI on time/35 min off time                                                                                      |
| MANUAL MODE DUTY CYCLE:                         | 5 min on time/30 min off time                                                                                               |
| APPROXIMATE INFLATION TIME at 13.8V (0-40 PSI): | 3.8 min +/- 10% with 205-65R16 95H Tire                                                                                     |
| AIR HOSE LENGTH:                                | 3 ft                                                                                                                        |
| POWERCORD LENGTH:                               | 10 ft                                                                                                                       |
| WIRE GAUGE:                                     | 18 AWG                                                                                                                      |
| POWER TYPE:                                     | 12V Plug                                                                                                                    |
| IP RATING:                                      | IP55                                                                                                                        |
| COOLING:                                        | Natural Convection                                                                                                          |
| OPERATING TEMPERATURE:                          | -4° to 122° F (-20° to +50° C)                                                                                              |
| STORAGE TEMPERATURE:                            | -4° to 122° F (-20° to +50° C)                                                                                              |
| WEIGHT:                                         | 5.39 lbs (2.44 kg)                                                                                                          |
| VOLUMETRICS:                                    | <b>Retail Packaging:</b><br>Dimensions: 10.83" x 4.41" x 8.54"<br>Weight: 7.30 lbs<br>UPC: 0-46221-23002-4                  |
|                                                 | <b>Master Carton:</b><br>Dimensions: 11.06" x 18.50" x 11.89"<br>Weight: 31.72 lbs<br>Quantity: 4<br>ITF-14: 10046221230021 |
|                                                 | <b>Inner Carton:</b><br>Dimensions: 11.34" x 8.98" x 5.04"<br>Weight: 7.63 lbs                                              |
|                                                 | <b>Units Per Pallet:</b><br>NA: 128 units<br>AU/UK/HP/J: 96 units<br>EU/ND/RM/FN: 72 units                                  |

**NOCO**

30339 Diamond Parkway, #102  
Glenwillow, OH 44139 | USA  
1.800.456.6626

no.co

