



EAN: 4013288228338
Part number: 05075851001
Article number: 7515/16

Size: 175x125x60 mm
Weight: 609 g
Country of origin: CZ
Customs tariff number: 82041100

- Torque screwdriver with quick torque adjustment
- Easy and quick torque setting
- Fixed position (Torque Lock) for unlimited tightening and loosening moments
- Secure slip-over torque function for clockwise/anti-clockwise torque-control
- Quick and easy setting of the selectable tightening torques (2.0; 3.0; 4.0; 5.0; 6.0 Nm)
- For bits with 1/4" external hexagon drive, also suitable for socket wrench inserts via adapter - ideal for bike operations
- Tools with Hex-Plus profile prevent premature rounding of hexagonal socket screws
- Suitable for docking with the Wera 2go system

16-piece tool set. For professional screwdriving/professional fine adjustment AND for torque-controlled screwdriving. Secure slip-over torque mechanism with quick clockwise/counterclockwise setting and five selectable tightening torques (2.0; 3.0; 4.0; 5.0; 6.0 Nm) and one fixed position (Torque Lock) for unlimited loosening and tightening moments. Quick-release holder for high robustness. Suitable for bits with 1/4" external hexagon drive. 15 tough bits (89 mm length).



Web link
<https://www.wera.de/en/05075851001>

Wera - 7515/16
 05075851001 - 4013288228338

Wera Werkzeuge GmbH
 Korzter Straße 21-25
 D-42349 Wuppertal
 Tel: +49 (0)2 02 / 40 45-0
 E-Mail: info@wera.de

Five selectable tightening torques



Torque screwdriver with quick torque adjustment




Five selectable tightening torques (2.0; 3.0; 4.0; 5.0; 6.0 Nm) and one fixed position (Torque Lock) for unlimited tightening and loosening moments.

Setting with Speed



Rapid setting of the selectable tightening torques.

Excess-load signal

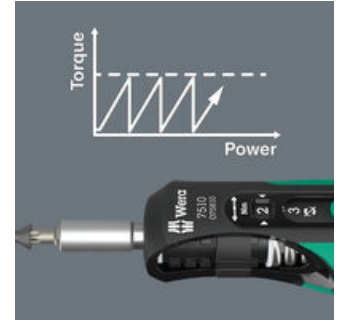


Distinctly audible and noticeable excess-load signal when the pre-set torque is reached.

Storage and transport



Storage and transport in a robust and compact textile roll pouch, so the tool is always close at hand.

Flexible due to hook-and-loop fastener strips

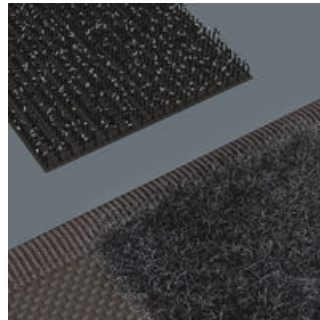

The textile box features a fleece zone at the back. Using the provided self-adhesive hook-and-loop fastener strips, the textile box can be attached to the Wera 2go components. Or to the wall, shelf or workshop trolley.

Web link

<https://www.wera.de/en/05075851001>

Wera - 7515/16
05075851001 - 4013288228338

Wera Werkzeuge GmbH
Korzerter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de

Set contents:

7515 Kraftform Safe-Torque Speed Torque screwdriver, 2-6 Nm, 1/4" x 2.0 Nm x 3.0 Nm x 4.0 Nm x 5.0 Nm x 6.0 Nm x 147.5 mm

05075815001	1x	1/4" x 2.0 Nm x 3.0 Nm x 4.0 Nm x 5.0 Nm x 6.0 Nm x 147.5 mm
-------------	----	--



851/4 Z bits, PH 2 x 89 mm



05059775001	1x	PH 2 x 89 mm
-------------	----	--------------



867/4 Z TORX® B0 bits with bore hole, TX 10 x 89 mm



05060050001	1x	TX 10 x 89 mm
05060051001	1x	TX 15 x 89 mm
05060052001	1x	TX 20 x 89 mm
05060053001	1x	TX 25 x 89 mm
05060054001	1x	TX 30 x 89 mm

867/4 IP TORX PLUS® bits, 10 IP x 89 mm



05134671001	1x	10 IP x 89 mm
05134672001	1x	15 IP x 89 mm
05134673001	1x	20 IP x 89 mm
05134674001	1x	25 IP x 89 mm
05134676001	1x	30 IP x 89 mm

840/4 Z bits, 3 x 89 mm



05059630001	1x	3 x 89 mm
05059631001	1x	4 x 89 mm
05059632001	1x	5 x 89 mm
05059633001 ¹⁾	1x	6 x 89 mm

1) Hexagonal blade

Web link

<https://www.wera.de/en/05075851001>

Wera - 7515/16

05075851001 - 4013288228338

Wera Werkzeuge GmbH

Korzerter Straße 21-25

D-42349 Wuppertal

Tel: +49 (0)2 02 / 40 45-0

E-Mail: info@wera.de