



Twist Off Cable Ties

- Worldwide patented cable ties for fast, trouble free bundling of cables, harnesses, wires, hoses, etc.
- Industrial quality strength.
- Indoor / outdoor use.
- Does not require a knife or scissors. Simply twist the tie and it snaps off. No sharp edges after breaking.
- Industrial quality strength. 100% nylon. Material is UL compliant.
- Rated for outdoor use.
- Suitable for use in air handling spaces in accordance with Section 300.22 (C) and (D) of the National Electrical Code.
- CE certified.
- Manufactured in Taiwan.
- Private brand option available.
- Shipping from the US packaging and warehousing facility
- Standard pack size is 100 cable ties (50 on the largest size.)
- Custom pack sizes are no problem.

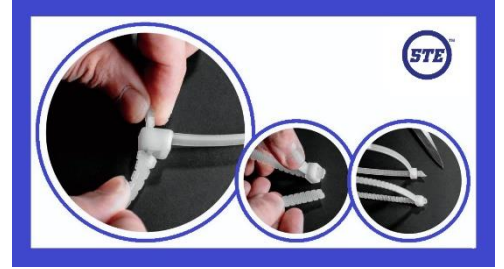

Scan QR code to watch demonstration video.

Examples of applications: Electrical, HVAC, Construction, Packaging Products, Industrial MRO, Electronic, Lawn and Garden, Automotive, Telecom.

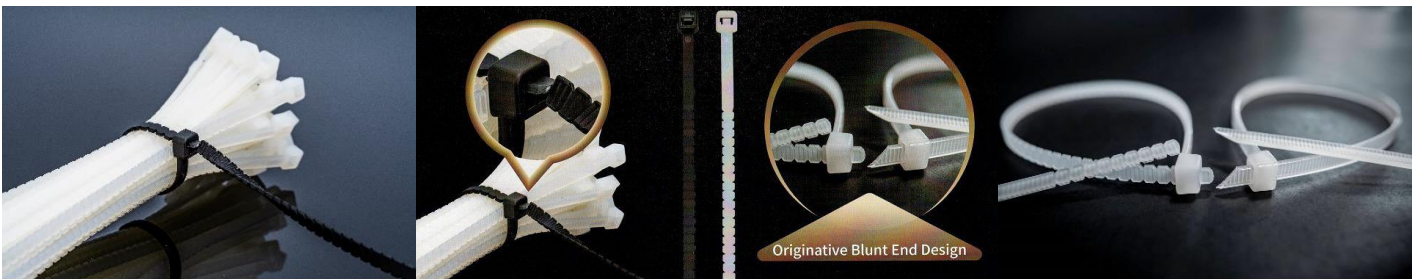

Item Number	Length (mm)	Width (mm)	Max Bundle Diameter	Tensile Strength	Packaging (pcs & bags)	Color
STW-102	102/ 4"	2.8	20mm/0.7inch	8kgs/18lbs	100pcs & 120 bags	Black & Natural
STW-150	150/ 6"	2.8	35mm/1.4inch	8kgs/18lbs	100pcs & 90 bags	Black & Natural
MTW-200	200/ 8"	4.6	47mm/1.9inch	22kg/50lbs	100pcs & 40 bags	Black & Natural
MTW-300	300/ 12"	4.6	78mm/3.1inch	22kg/50lbs	100pcs & 35 bags	Black & Natural
LTW-360	360/ 14"	8	92mm/3.6inch	54kg/120lbs	100pcs & 20 bags	Black & Natural
LTW-504	504/ 20"	8	138mm/5.4inch	54kg/120lbs	100pcs & 15 bags	Black & Natural