


# Rolled Steel AC Motors, Single Phase



## Features

- Totally Enclosed Fan Cooled (TEFC) enclosure
- Dual mounting with NEMA 56C and removable base
- Class F insulation
- Rolled steel shell frame / cast aluminum end bell
- Removable base / bolt-on/bolt-off mounting feet
- Large all-metal capacitor cover with rubber gasket
- Large easy-to-wire junction box with rubber gasket
- Heavy duty oversized ball bearings
- High tensile strength steel shaft
- Electrically reversible
- NEMA design B
- Service Factor: 1.15

| Item #  | HP  | RPM  | Voltage     | Frame | Encl. | O (max) | C (max) | F.L Amps | S. F. | Weight |
|---------|-----|------|-------------|-------|-------|---------|---------|----------|-------|--------|
| MA0503B | 1/3 | 3450 | 115/208-230 | 56C   | TEFC  | 6.5     | 12.5    | 4.4/2.2  | 1.15  | 21     |
| MA0505B | 1/2 | 3450 | 115/208-230 | 56C   | TEFC  | 6.5     | 12.5    | 8.4/4.2  | 1.15  | 23     |
| MA0507B | 3/4 | 3450 | 115/208-230 | 56C   | TEFC  | 6.5     | 13.5    | 10.6/5.3 | 1.15  | 25     |
| MA0510B | 1   | 3450 | 115/208-230 | 56C   | TEFC  | 6.5     | 13.5    | 11.2/5.6 | 1.15  | 30     |
| MA0515B | 1.5 | 3450 | 115/208-230 | 56C   | TEFC  | 6.5     | 15.1    | 14.2/7.1 | 1.15  | 38     |
| MA0520B | 2   | 3450 | 115/208-230 | 56C   | TEFC  | 6.5     | 15.1    | 16.6/8.3 | 1.15  | 42     |

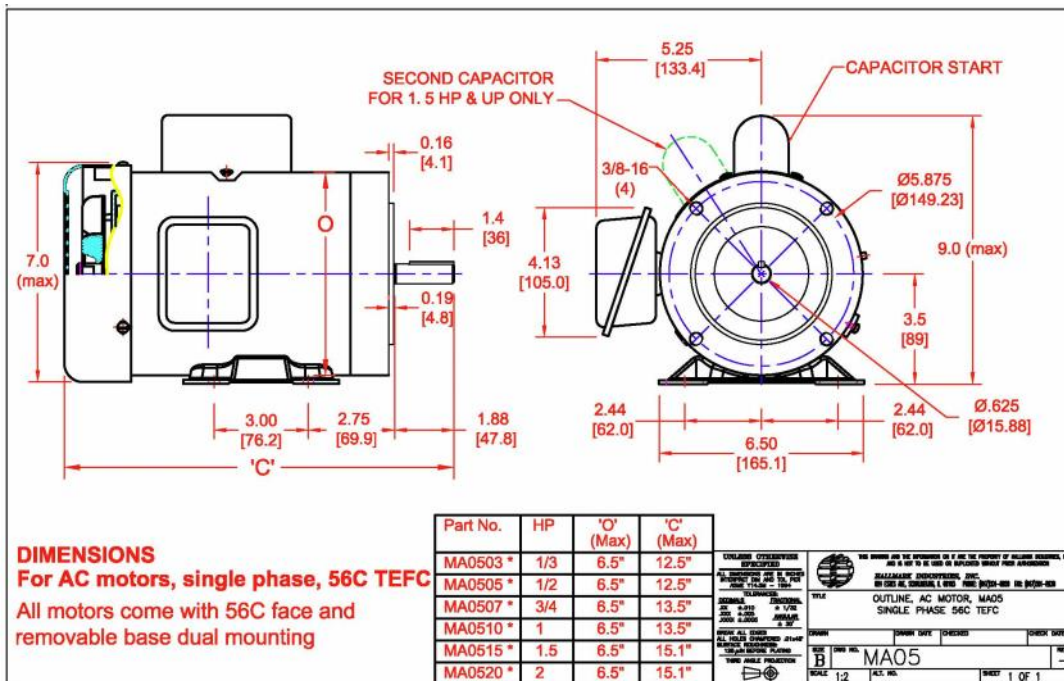

# HALLMARK INDUSTRIES, INC.