

GIOVANNI

B1035-PBR

Conceived as a wall-mounted light sculpture, the Giovanni sconce features six dome heads radiating like spokes from a central hub. Fitted with LED, each dome projects a wash of indirect light onto the wall, illuminating the striking graphic form and creating a soft ambient effect. Finished in Patina Brass, Giovanni blends modernity with an air of permanence.

FINISHES

PATINA BRASS

Coastal Suitable Finish (EPM): No

DIMENSIONS

Height: 34.75"

Width/Diameter: 24.5"

Length: 3.75"

Canopy/Backplate: 4.75"

Product Weight: 7lb

Top to Center: 17.5"

Canopy/Backplate Shape: Round

Sloped Ceiling Compatible: No

Living Finish: No

Uplight Only: No

Shade

ELECTRICAL



Bulb 1

Bulb Included: N/A

Socket: Integrated LED

Max Wattage: 33

Bulb Quantity: 6

Wire Length: 7"

Cord Type: B & W TEFLON W/ GROUND WIRE

Gem Box Required (2"x3"): No

Dark Sky: No


CRI: 90

Color Temp.: 2700k

Lumens: 2125

Title 24: No

Field Serviceable: No

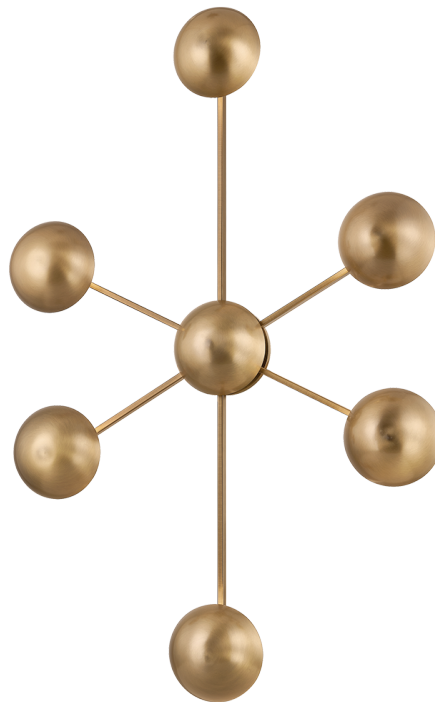

SHIPPING

Carton 1: 39" x 24" x 6"

Carton 1 Weight: 10lb

Shipping Method: Ground

Country of Origin: VN