

E26 Screw Base H645IC Slope Trims

IC Slope Housings: H645IC

6
INCH

455 Specular Reflector

- Clear, gold or haze reflector
- Removable trim ring
- Accessories available: TRM6 designer trim rings, OT403 oversize trim ring

Housing	Max Lamp Compatibility
H645IC	65W BR30, 75W R30, 75W PAR30L



 
455SC
Specular Clear Reflector,
White Trim



455H
Haze Reflector, White Trim



455CG
Champagne Gold Reflector,
White Trim



Dimensions**
OD: 7-1/4" [184mm]

456 Seamless Coilex® Baffle Trims

- One piece seamless baffle
- Accessories available: TRM6 designer trim rings, OT403 oversize trim ring


Housing	Max Lamp Compatibility
H645IC	456W: 50W PAR30L, 65W BR30 (75W PAR30L with H1999 Socket Extender)
	456P: 60W BR30, 50W PAR30L



456W
White Coilex Baffle,
White Metal Trim



 456P
Black Coilex Baffle,
White Metal Trim



Dimensions**
OD: 7-1/4" [184mm]

Accessory - H1999



Socket Extender

78 Eyeball 30° Tilt, Self-flange

- 30° tilt, 360° rotation
- Torsion spring retention
- Wide choice of finishes for any decor
- Socket supporting eyeball
- 78PAT makes installation Air-Tite regardless of housing used

Housing	Max Lamp Compatibility
H645IC	65W BR30, 75W R30, 75W PAR30L



78P
White Eyeball, White Trim




78PAT
White Eyeball, White Trim



78SN
Satin Nickel Eyeball,
Satin Nickel Trim



78TBZ
Tuscan Bronze Eyeball,
Tuscan Bronze Trim

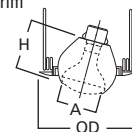

Dimensions**
A: 4" [100mm]
H: 4-1/8" [105mm]
OD: 8" [203mm]

170 Albalite Glass Lens with Reflector

- White trim with Albalite glass lens
- PS version features non-conductive, non-corrosive gasketed polymer (plastic) trim ring
- PS version is "dead-front" construction and is wet location listed for use in showers
- Torsion spring retention
- PS version is Air-Tite; making any installation Air-Tite


Housing	Max Lamp Compatibility
H645IC	60W A19



170P
Albalite Lens, White Trim



170PS
Albalite Lens, White Polymer Trim

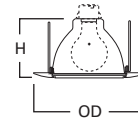

Dimensions**
H: 4" [102mm]
OD: 8" [203mm]

**Key: A: Luminous Aperture, H: Height, OD: Trim Outside Diameter

Specifications, compliances and dimensions subject to change without notice