



**MCR
SAFETY**

4320

Welder Specification Sheet

PRODUCT DESCRIPTION:

MCR Safety has the perfect welders glove to fit you individual needs. From premium options sewn with DuPont™ Kevlar® thread that provide maximum protection in conditions where users are exposed to heat, flame, and spark to rugged economical options that keep you safe and secure, we have you covered. The 4320 is a Premium Select shoulder leather welders glove that is russet in color. It also features a reinforced straight thumb and DuPont™ Kevlar® stitching. Left Hand Only Option Available = 4320LH



FEATURES:

- Sewn with Dupont™ Kevlar® thread
- Premium Select shoulder leather
- Reinforced straight thumb
- Russet color
- 1 pc back, welted and lined

APPLICATIONS:

Construction, Heliarc, Iron work , Mig/Tig, Ship building, Steel Work, Welding

TECHNICAL DATA FOR: 4320

Material Group	Leather	ANSI Puncture	5
Product Type	Welder	ANSI Abrasion	4
Glove Size	X - Large	ANSI Contact Heat	3 - Less than 392°F
Material	Leather		
Leather Cut	Split Select Shoulder		
Leather Type	Cow		
Grade	Select Grade		
Features	Sewn With KEVLAR		
Insulated	Yes		
Lining	Fleece		
Pattern	Gunn		
Thumb Style	Straight		
Thickness	1.1 - 1.6 mm		

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2021 MCR Safety - All Rights Reserved




MCR
SAFETY

4320

Welder
Specification Sheet

Made In

China

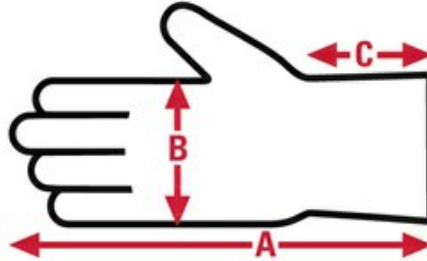

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
4320	X - Large	13.625	5.625	5.250	65.622 lb.	10.937
4320LH	X - Large	13.625	5.625	5.250	61.488 lb.	0.427

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2021 MCR Safety - All Rights Reserved