

## Flush Rectangular Non-Metallic Floor Boxes with Metal Covers

Style	1-Gang	2-Gang	3-Gang
	<p><b>PFBRG1*</b></p>	<p><b>PFBRG2</b></p>	<p><b>PFBRG3</b></p>
Min. Depth of Pour	3.00" (76.2)	3.00" (76.2)	3.00" (76.2)
Adjustability	Fully	Fully	Fully
Cubic Inch (cm <sup>3</sup> ) Capacity per Gang	14.3 cu. in. (234.3 cm <sup>3</sup> ) per 1" depth	14.3 cu. in. (234.3 cm <sup>3</sup> ) per 1" depth	14.3 cu. in. (234.3 cm <sup>3</sup> ) per 1" depth
Dimensions – A	6.00" (152.4)	6.00" (152.4)	6.00" (152.4)
Dimensions – B	3.60" (91.4)	6.80" (172.7)	10.04" (255.0)
Dimensions – C	5.47" (138.9)	5.47" (138.9)	5.47" (138.9)
Dimensions – D	6.90" (175.3)	6.90" (175.3)	6.90" (175.3)
Dimensions – E	5.41" (137.4)	8.56" (221.4)	11.75" (298.4)
Hubs	(4) 1¼"	(6) 1¼"	(8) 1¼"
Reducers	(4) 1" to ¾" and (4) 1¼" to 1"	(6) 1" to ¾" and (6) 1¼" to 1"	(8) 1" to ¾" and (8) 1¼" to 1"
Concrete Cover Included	✓	✓	✓
Closure Plugs Included	✓	✓	✓
Removable LV Barrier	–	✓	✓

Note: UL File Number E92074.

\*Suitable for single service applications only.

## Flush Rectangular Metal Covers and Flanges

### Required Components for Carpet and Tile Applications

Adapter Collar (One required per gang)	Adapter Frame with Grounding Lug (One required per gang) Dim. 4.36" x 3.20"
Gray <b>PFBRAC</b>	Brass <b>S5017G</b> Aluminum <b>SA5017G</b>

## Flush Rectangular Metal Covers and Flanges

### Required Components for Carpet and Tile Applications

Adapter Collar (One required per gang)
Gray <b>PFBRAC</b>

## Carpet Flanges (Not Required for Tile Applications)

### Tapered Flange

Number of Gangs	1-Gang	2-Gang	3-Gang
Dimensions	6.00" x 4.85"	6.00" x 8.13"	6.00" x 11.34"
Brass	<b>SB3083</b>	<b>SB3084</b>	<b>SB3085</b>
Aluminum	<b>SA3083</b>	<b>SA3084</b>	<b>SA3085</b>



## Rectangular Flanges (Required)

Number of Gangs	1-Gang	2-Gang	3-Gang
Dimensions	6.00" x 4.85"	6.00" x 8.13"	6.00" x 11.34"
Brass	<b>SB3083W</b>	<b>SB3084W</b>	<b>SB3085W</b>
Aluminum	<b>SA3083W</b>	<b>SA3084W</b>	<b>SA3085W</b>



## Covers – One Required per Gang

Brass	<b>S3825</b>	<b>S3625</b>	<b>S3826</b>	<b>S2425</b>	<b>S2625</b>	<b>S2825</b>	<b>S3813</b>
Aluminum	<b>SA3825</b>	<b>SA3625</b>	<b>SA3826</b>	<b>SA2425</b>	<b>SA2625</b>	–	<b>SA3813</b>
Dimensions	4.15" x 2.99"						
	Duplex Flap	Duplex Screw	Style Line® Decorator Opening	2½" x ¾" Combination	2½" x 1" Combination	2½" Single Receptacle	Blank

Dimensions in Inches (mm)

## Flush Rectangular Cast Iron Floor Boxes, for Use In Concrete Floors

Style	Cast Iron											
	1-Gang Deep		2-Gang Deep		3-Gang Deep		1-Gang Shallow		2-Gang Shallow		3-Gang Shallow	
Collar Material:												
Brass	<b>B2436*</b>	<b>B243641*</b>	<b>B4233</b>	<b>B423341</b>	<b>B4333</b>	<b>B433361</b>	<b>B2437*</b>	<b>B2414*</b>	<b>B4214</b>	<b>B4314</b>	<b>B4314</b>	<b>B4314</b>
Aluminum	<b>BA2436*</b>	<b>BA243641*</b>	<b>BA4233</b>	<b>BA423341</b>	<b>BA4333</b>	<b>BA433361</b>	<b>BA2437*</b>	<b>BA2414*</b>	<b>BA4214</b>	<b>BA4314</b>	<b>BA4314</b>	<b>BA4314</b>
Min. Depth of Pour	3.25" (82.5)	3.50" (95.3)	3.50" (95.3)	3.50" (95.3)	3.00" (76.2)	2.00" (50.8)	2.00" (50.8)	2.00" (50.8)	2.00" (50.8)	2.00" (50.8)	2.00" (50.8)	2.00" (50.8)
Adjustability	Fully	Fully	Fully	Fully	Fully	Semi	Semi	Semi	Semi	Semi	Semi	Semi
Before Pour External Height Adjustment	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)
After Pour Internal Height Adjustment	.38" (9.5)	.63" (15.9)	.63" (15.9)	.63" (15.9)	.38" (9.5)	-	-	-	-	-	-	-
Cubic Inch (cm <sup>3</sup> ) Capacity per Gang	33.0 cu. in. (540.7 cm <sup>3</sup> )	36.5 cu. in. (598.1 cm <sup>3</sup> )	34.8 cu. in. (570.3 cm <sup>3</sup> )	34.8 cu. in. (570.3 cm <sup>3</sup> )	30.0 cu. in. (491.7 cm <sup>3</sup> )	16.0 cu. in. (262.2 cm <sup>3</sup> )	16.0 cu. in. (262.2 cm <sup>3</sup> )	16.0 cu. in. (262.2 cm <sup>3</sup> )	16.0 cu. in. (262.2 cm <sup>3</sup> )	16.0 cu. in. (262.2 cm <sup>3</sup> )	16.0 cu. in. (262.2 cm <sup>3</sup> )	16.0 cu. in. (262.2 cm <sup>3</sup> )
Dimensions – A	3.15" (80.0)	3.38" (85.9)	3.38" (85.9)	3.38" (85.9)	2.90" (73.7)	2.00" (50.8)	2.00" (50.8)	2.00" (50.8)	2.00" (50.8)	2.00" (50.8)	2.00" (50.8)	2.00" (50.8)
Dimensions – B	4.69" (119.1)	4.84" (122.9)	4.90" (122.5)	4.90" (122.5)	4.69" (119.1)	5.46" (138.7)	5.46" (138.7)	5.46" (138.7)	5.46" (138.7)	5.46" (138.7)	5.46" (138.7)	5.46" (138.7)
Dimensions – C	4.69" (119.1)	8.06" (204.7)	11.41" (289.8)	11.41" (289.8)	4.69" (119.1)	4.19" (106.4)	7.49" (190.2)	7.49" (190.2)	7.49" (190.2)	10.7" (271.8)	10.7" (271.8)	10.7" (271.8)
Dimensions – D	4.36" (110.7)	4.36" (110.7)	4.36" (110.7)	4.36" (110.7)	4.36" (110.8)	4.36" (110.8)	4.36" (110.8)	4.36" (110.8)	4.36" (110.8)	4.36" (110.8)	4.36" (110.8)	4.36" (110.8)
Dimensions – E	3.20" (81.3)	6.42" (163.1)	9.64" (244.9)	9.64" (244.9)	3.20" (81.3)	3.20" (81.3)	3.20" (81.3)	6.38" (162.1)	6.38" (162.1)	9.56" (242.8)	9.56" (242.8)	9.56" (242.8)
Threaded Hubs	(4) 3/4" (4) 1" & (2) 3/4"	(6) 3/4" (4) 1" & (2) 3/4"	(8) 3/4" (6) 1" & (2) 3/4"	(8) 3/4" (6) 1" & (2) 3/4"	(4) 3/4"	(4) 3/4"	(4) 3/4"	(4) 3/4"	(4) 3/4"	(6) 3/4"	(6) 3/4"	(6) 3/4"
Concrete Cover Included	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓
Closure Plugs Included	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓	✓
Removable LV Barrier	-	✓	✓	✓	-	-	-	-	-	-	-	-

Note: UL File Number E92074.  
CSA File Number LR18416.  
\*Suitable for single service applications only.

## Carpet Flanges

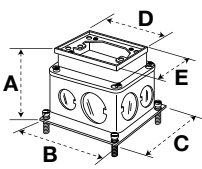
 







Tapered Flange		1-Gang		2-Gang		3-Gang	
Number of Gangs	Dimensions	6.00" x 4.85"		6.00" x 8.13"		6.00" x 11.34"	
Brass	<b>SB3083</b>		<b>SB3084</b>		<b>SB3085</b>		
Aluminum	<b>SA3083</b>		<b>SA3084</b>		<b>SA3085</b>		
Clear Polycarbonate	<b>S3083</b>		<b>S3084</b>		<b>S3085</b>		

## Covers – One Required per Gang

Brass	<b>S3825</b>	<b>S3625</b>	<b>S3826</b>	<b>S2425</b>	<b>S2625</b>	<b>S2825</b>	<b>S3813</b>
Aluminum	<b>SA3825</b>	<b>SA3625</b>	<b>SA3826</b>	<b>SA2425</b>	<b>SA2625</b>	-	<b>SA3813</b>
Dimensions	4.15" x 2.99"						
	Duplex Flap	Duplex Screw	Style Line® Decorator Opening	2 1/2" x 3/4" Combination	2 1/2" x 1" Combination	2 1/2" Single Receptacle	Blank

Dimensions in Inches (mm)

## Flush Rectangular Stamped Steel Floor Boxes, for Use In Concrete Floors




Style	Stamped Steel							
	1-Gang Deep	2-Gang Deep	3-Gang Deep	1-Gang Shallow	2-Gang Shallow	3-Gang Shallow	1-Gang Deep	1-Gang Shallow
								
Collar Material: Brass Aluminum	<b>B2431*</b> <b>BA2431*</b>	<b>B2432</b> <b>BA2432</b>	<b>B2433</b> <b>BA2433</b>	<b>B2421*</b> <b>BA2421*</b>	<b>B2422</b> <b>BA2422</b>	<b>B2423</b> <b>BA2423</b>	<b>B2427*</b> <b>BA2427*</b>	<b>B2429*</b> <b>BA2429*</b>
Min. Depth of Pour	3.75" (95.3)	3.75" (95.3)	3.75" (95.3)	2.75" (69.9)	2.75" (69.9)	2.75" (69.9)	4.00" (101.6)	3.00" (76.2)
Adjustability	Fully	Fully	Fully	Fully	Fully	Fully	Fully	Fully
Before Pour External Height Adjustment	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)	1.25" (31.8)
After Pour Internal Height Adjustment	.50" (12.7)	.50" (12.7)	.50" (12.7)	.50" (12.7)	.50" (12.7)	.50" (12.7)	.38" (9.5)	.38" (9.5)
Cubic Inch (cm <sup>3</sup> ) Capacity per Gang	60.0 cu. in. (983.2 cm <sup>3</sup> )	52.8 cu. in. (865.2 cm <sup>3</sup> )	50.8 cu. in. (832.5 cm <sup>3</sup> )	39.5 cu. in. (647.3 cm <sup>3</sup> )	35.0 cu. in. (573.5 cm <sup>3</sup> )	34.0 cu. in. (557.2 cm <sup>3</sup> )	54.0 cu. in. (884.9 cm <sup>3</sup> )	37.3 cu. in. (611.2 cm <sup>3</sup> )
Dimensions – A	3.72" (94.5)	3.72" (94.5)	3.72" (94.5)	2.74" (69.6)	2.74" (69.6)	2.74" (69.6)	3.90" (99.1)	2.81" (71.4)
Dimensions – B	4.81" (122.2)	4.81" (122.2)	4.81" (122.2)	4.81" (122.2)	4.81" (122.2)	4.81" (122.2)	6.00" (152.4)	6.00" (152.4)
Dimensions – C	6.00" (152.4)	9.25" (235.0)	12.50" (317.5)	6.00" (152.4)	9.25" (235.0)	12.50" (317.5)	4.81" (122.2)	4.81" (122.2)
Dimensions – D	4.36" (110.7)	4.36" (110.7)	4.36" (110.7)	4.36" (110.7)	4.36" (110.7)	4.36" (110.7)	4.36" (110.7)	4.36" (110.7)
Dimensions – E	3.20" (81.3)	6.44" (163.6)	9.67" (245.6)	3.20" (81.3)	6.44" (163.6)	9.67" (245.6)	3.20" (81.3)	3.20" (81.3)
Knockouts – Sides	(1) ¼", 1", 1¼"	(2) ¼", 1", 1¼"	(3) ¼", 1", 1¼"	(2) ½", (1) ¾"	(4) ½", (2) ¾"	(6) ½", (6) ¾"	(1) ½", (1) 1¼"	(2) ½", (1) ¾"
Knockouts – Ends	(1) ¼", 1", 1¼"	(1) ¼", 1", 1¼"	(1) ¼", 1", 1¼"	(1) ½", (1) ¾"	(2) ½", (2) ¾"	(2) ½", (2) ¾"	(1) ¾", (1) 1"	(1) ½", (1) ¾"
Knockouts – Bottom	(2) ¼", 1", 1¼"	(4) ¼", 1", 1¼"	(6) ¼", 1", 1¼"	(2) ¾", 1", 1¼"	(4) ¾", 1", 1¼"	(6) ¾", 1", 1¼"	(3) ½", (2) ¾"	(3) ½", (2) ¾"
Concrete Cover Included	✓	✓	✓	✓	✓	✓	✓	✓
Closure Plugs Included	-	-	-	-	-	-	-	-
Removable LV Barrier	-	✓	✓	-	✓	✓	-	-

Note: UL File Number E92074.








CSA File Number LR18416.

\*Suitable for single service applications only.

## Carpet Flanges

Tapered Flange		1-Gang		2-Gang		3-Gang	
Number of Gangs	Dimensions	6.00" x 4.85"		6.00" x 8.13"		6.00" x 11.34"	
Brass	<b>SB3083</b>		<b>SB3084</b>		<b>SB3085</b>		
Aluminum	<b>SA3083</b>		<b>SA3084</b>		<b>SA3085</b>		
Clear Polycarbonate	<b>S3083</b>		<b>S3084</b>		<b>S3085</b>		

## Covers – One Required per Gang

Brass	<b>S3825</b>	<b>S3625</b>	<b>S3826</b>	<b>S2425</b>	<b>S2625</b>	<b>S2825</b>	<b>S3813</b>
Aluminum	<b>SA3825</b>	<b>SA3625</b>	<b>SA3826</b>	<b>SA2425</b>	<b>SA2625</b>	-	<b>SA3813</b>
Dimensions	4.15" x 2.99"						
							
	Duplex Flap	Duplex Screw	Style Line® Decorator Opening	2½" x ¾" Combination	2½" x 1" Combination	2½" Single Receptacle	Blank

Dimensions in Inches (mm)

## Flush Floor Boxes for Wooden Floors

Style		Rectangular Stamped Steel			Round Cast Iron	
		1-Gang	2-Gang	3-Gang	1-Gang	1-Gang
		<b>B2481*</b>	<b>B2482</b>	<b>B2483</b>	<b>B2588*</b>	<b>B2588275*</b>
Adjustability		Semi	Semi	Semi	Non	Non
Cubic Inch (cm <sup>3</sup> ) Capacity per Gang		42.0 cu. in. (688.3 cm <sup>3</sup> )	42.5 cu. in. (696.5 cm <sup>3</sup> )	42.5 cu. in. (696.5 cm <sup>3</sup> )	18.5 cu. in. (303.2 cm <sup>3</sup> )	18.5 cu. in. (303.2 cm <sup>3</sup> )
Dimensions – A		3.13" (79.5)	3.13" (79.5)	3.13" (79.5)	3.65" (92.7)	3.65" (92.7)
Dimensions – B		4.50" (114.3)	4.50" (114.3)	4.50" (114.3)	3.22" (81.8)	3.22" (81.8)
Dimensions – C		3.20" (81.3)	6.42" (163.1)	9.64" (244.9)	4.09" (103.9)	4.09" (103.9)
Threaded Hubs		–	–	–	Bottom (2) ½"	Sides (2) ¾" Bottom (2) ½"
Knockouts – Ends		(1) ½", ¾", 1"	(2) ½", ¾", 1"	(3) ½", ¾", 1"	–	–
Knockouts – Sides		–	–	–	–	–
Knockouts – Bottom		(1) ½", ¾", 1", 1¼"	(2) ½", ¾", 1", 1¼"	(3) ½", ¾", 1", 1¼"	–	–
Debris Cover Included		✓	✓	✓	–	–
Closure Plugs Included		–	–	–	✓	✓
Removable LV Barrier		–	✓	✓	–	–

Note: UL File Number E31999. CSA File Number LR18416.  
\*Suitable for single service applications only.

### Rectangular Flanges (Required)

	<b>SB3083W</b>	<b>SB3084W</b>	<b>SB3085W</b>
Brass	<b>SB3083W</b>	<b>SB3084W</b>	<b>SB3085W</b>
Aluminum	<b>SA3083W</b>	<b>SA3084W</b>	<b>SA3085W</b>
No. of Gangs	1-Gang	2-Gang	3-Gang
Dimensions	6.00" x 4.85"	6.00" x 8.13"	6.00" x 11.34"

### Round Flanges

<b>S3182</b>	<b>S3082</b>
<b>SA3182</b>	<b>SA3082</b>
5.25" Dia.	6.25" Dia.

### Round Covers (3.88" Dia.)

<b>S3925</b>	<b>S3725</b>	<b>S2525</b>
<b>SA3925</b>	<b>SA3725</b>	<b>SA2525</b>
Duplex Flap	Duplex Screw	2 1/8" x 3/4" Comb.

### Covers – One Required per Gang

	<b>S3825</b>	<b>S3625</b>	<b>S3826</b>	<b>S2425</b>
Brass	<b>S3825</b>	<b>S3625</b>	<b>S3826</b>	<b>S2425</b>
Aluminum	<b>SA3825</b>	<b>SA3625</b>	<b>SA3826</b>	<b>SA2425</b>
Dimensions				
4.15" x 2.99"	Duplex Flap	Duplex Screw	Style Line® Decorator Opening	2 1/8" x 3/4" Combination
	<b>S2625</b>	<b>S2825</b>	<b>S3425</b>	<b>S3813</b>
Brass	<b>S2625</b>	<b>S2825</b>	<b>S3425</b>	<b>S3813</b>
Aluminum	<b>SA2625</b>	–	–	<b>SA3813</b>
Dimensions				
4.15" x 2.99"	2 1/8" x 1" Combination	2 1/8" Single Receptacle	2 3/8" Single Receptacle	Blank

### Round Covers

	<b>S2725</b>	<b>S2925</b>	<b>S3525</b>	<b>S3325</b>
Brass	<b>S2725</b>	<b>S2925</b>	<b>S3525</b>	<b>S3325</b>
Aluminum	<b>SA2725</b>	<b>SA2925</b>	–	–
3.88" Dia.				
	2 1/8" x 1" Comb.	2 1/8" Single Receptacle	2 3/8" Single Receptacle	2 1/8" Single Rec. (Terrazzo Floor)

### One Piece Brass Cover and Carpet Flange

	<b>SF3925</b>	<b>SF2525</b>	<b>SF2725</b>	<b>SF2925</b>
Brass	<b>SF3925</b>	<b>SF2525</b>	<b>SF2725</b>	<b>SF2925</b>
Aluminum	<b>SFA3925</b>	–	–	–
6.25" Dia.				
	Duplex Flap	2 1/8" x 3/4" Combination	2 1/8" x 1" Combination	2 1/8" Single Receptacle

Dimensions in Inches (mm)