


MASTER CHOICE

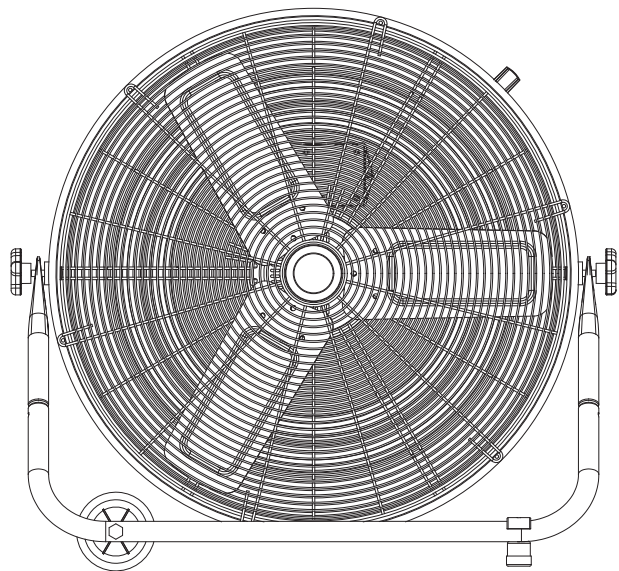

30 INCH INDUSTRIAL FAN

——FT-30 PLUS——

PRODUCT USE GUIDE

INTRODUCTION

Thank you for choosing our fan.
This owner's manual will provide you with valuable
information necessary for the proper care and
maintenance of your new product.
Please take a few minutes to read it.

TABLE OF CONTENTS

SECTION 1

IMPORTANT INSTRUCTIONS PAGES 3-4

SECTION 2

TECHNICAL PARAMETERS PAGES 4

PRODUCT DIAGRAM PAGES 4

PACKAGE INCLUDES PAGES 5

SECTION 3

ASSEMBLY INSTRUCTIONS PAGES 5-7

OPERATION INSTRUCTIONS PAGES 8

SECTION 4

STORAGE MAINTENANCE GUIDELINES PAGES 8

SECTION 5

WARRANTY & CONTACT US PAGES 9-10

⚠ IMPORTANT INSTRUCTIONS


PLEASE READ CAREFULLY- ALWAYS MAINTAIN SAFETY WHEN WORKING WITH ANY APPLIANCE.

1. Check that the mains voltage corresponds with the rating of the appliance before operating.
2. To protect against electric shock. Do not immerse cords plugs or appliances in water or any other liquid.
3. Do not leave any appliance unattended while it is operating.
4. Close supervision is necessary when any appliance is used by or near children or infirm persons.
5. Unplug from the outlet when not in use or before cleaning. Allow cooling before taking off any parts.
6. Do not operate the appliance with damaged power cords or plugs, and do not use a damaged appliance. If the power cord or appliance is damaged, it must be replaced by the manufacturer, service agent, or similarly qualified professional to avoid a hazard.
7. The use of accessory attachments not recommended by the appliance manufacturer may cause injuries.
8. Do not use outdoors.
9. Do not let the cord hang over the edge of a table or counter or let it come into contact with any hot surfaces
10. To disconnect-remove the plug from the outlet. Do not pull the plug out by the cord.
11. Do not use this product for anything other than its intended use. This appliance is for household use only.
12. No liability can be accepted for any damage caused by non-compliance with these instructions or any other improper use or mishandling.
13. Do not use the appliance without the protective grills.
14. Do not attempt to force the grill to make the fan turn or stop.
15. Never put objects into the grills when the appliance is connected to the mains.
16. It is not advisable to expose people(esp.. Babies or older people) to a continuous cold air stream for a long time.

TECHNICAL PARAMETERS

Model No.	FT-30 PLUS
Item Name	INDUSTRIAL FAN
Rated Voltage	120V (60Hz)
Rated Power	550W
3 Mode Fan Speeds	Low / Medium / High
Max Oscillation	360 Degrees
Fan Blade Diameter	30 Inch
Product Size	33.9×16.3×33.5 Inch


PRODUCT DIAGRAM

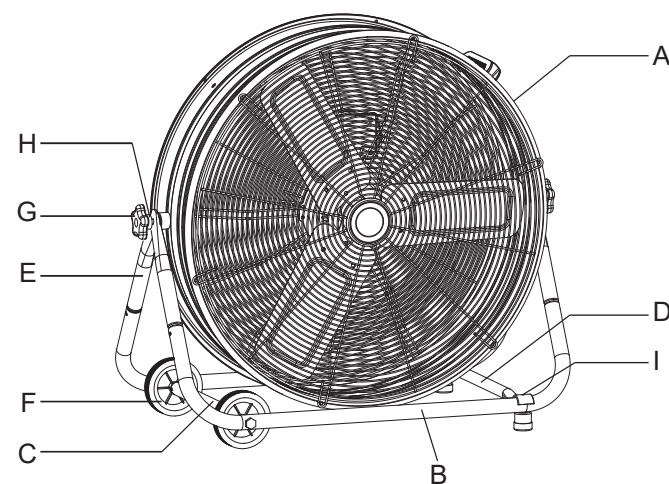

A — Product Body*1	D — Fixed Crossbeam*1	G — Plum Knob*2
B — U-Shaped Rod*2	E — Support Frame*4	H — Silicone Gasket*2
C — Wheel Crossbeam*1	F — Wheel*2	I — Crossbeam Screw*2

Note: For the convenience of transportation, two sets of plum knobs and silicone gaskets will be locked on the main body of the product. Please dismantle in advance when assembling the product.


PACKAGE INCLUDE

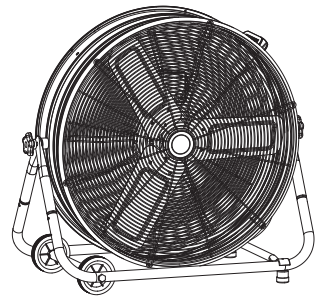

1 × Industrial Fan




1 × Screwdriver

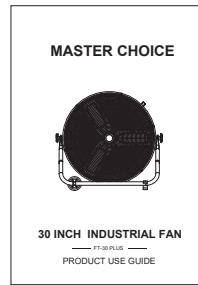

1 × Owner's Manual


ASSEMBLY INSTRUCTIONS

Step 1: Rotate and remove the two plum knobs and silicone gasket on the product.

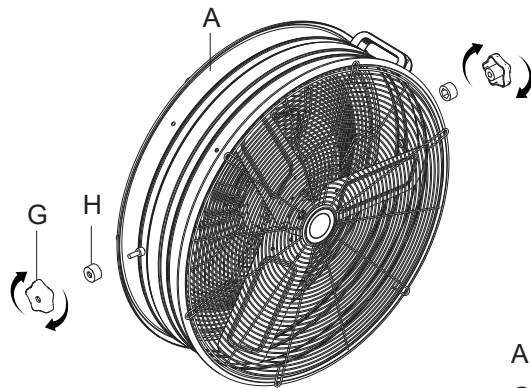


A — Product Body
G — Plum Knob
H — Silicone Gasket

Step 2: Install the two support frames as the figure shows. Repeat once, and install the other side.

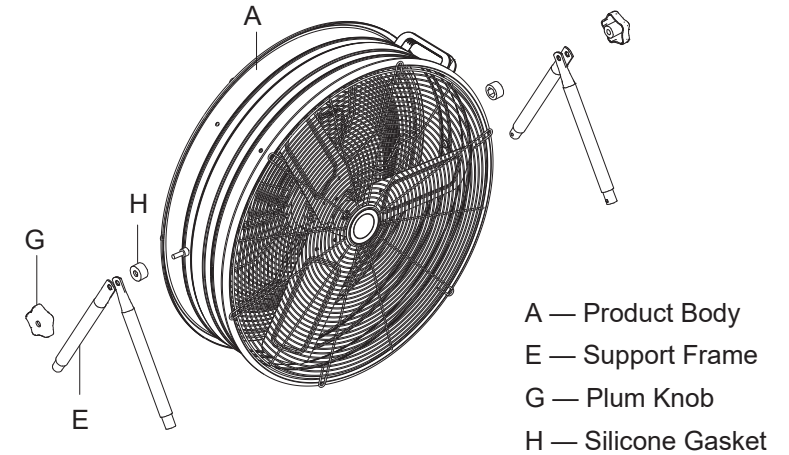


A — Product Body
E — Support Frame
G — Plum Knob
H — Silicone Gasket

Step 3: Rotate and remove the screws and gasket on the left and right sides of the wheel crossbeam.

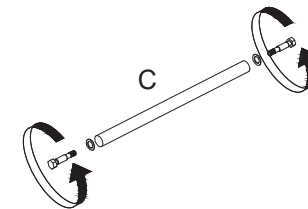


C — Wheel Crossbeam

Step 4: Install the two U-shaped rods and wheels as the figure shows.

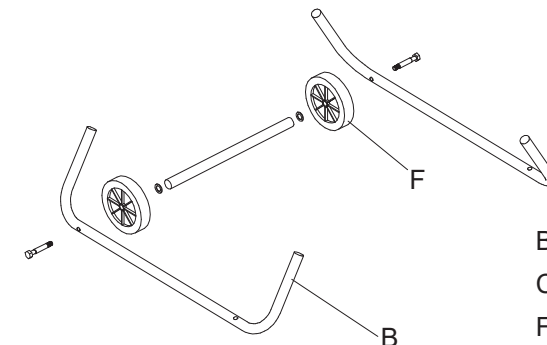


B — U-Shaped Rod
C — Wheel Crossbeam
F — Wheel

Step 5: Fasten the fixed crossbeam with screws.

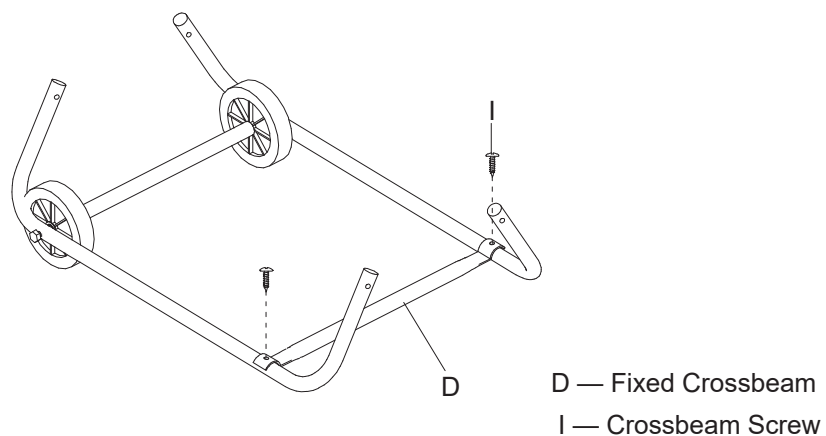

Step 6: Remove the four screws on the support frames, put the support frames on the U-shaped rods, and lock it with the screws.

NOTE : If the angle of the support frame is not enough, loosen the plum knob to adjust.

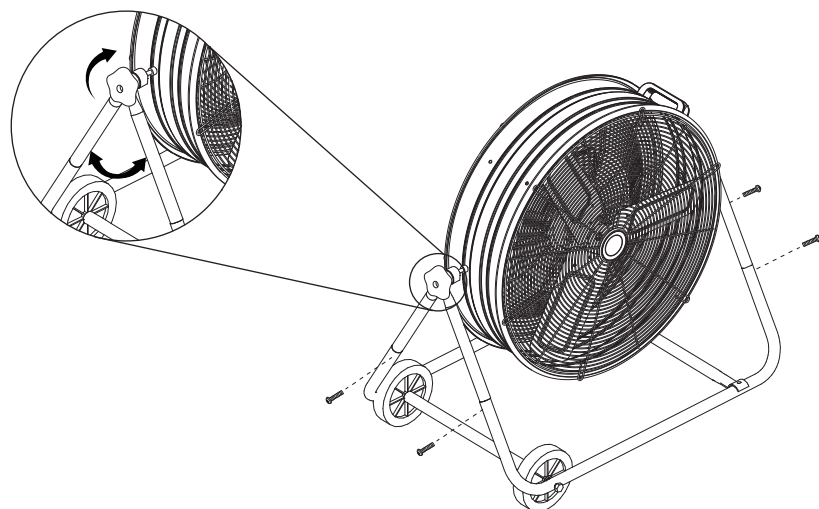

OPERATION INSTRUCTIONS

1. Plug the power cord into 120V the volt AC wall outlet.
2. You can turn the switch to 1, 2, or 3 to select low / medium / high speed(Figure A)
3. You can loosen the plum knobs and adjust the vertical oscillation of the fan, max 360 degrees (Figure B)

NOTE : After the product body angle is adjusted to 180°, the handle will rotate to the bottom of the fan. If you want to use the handle, please adjust it by another 180°.

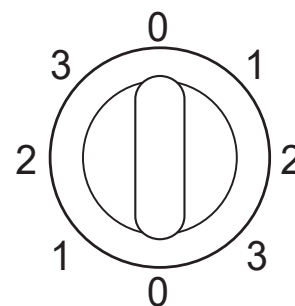


Figure A

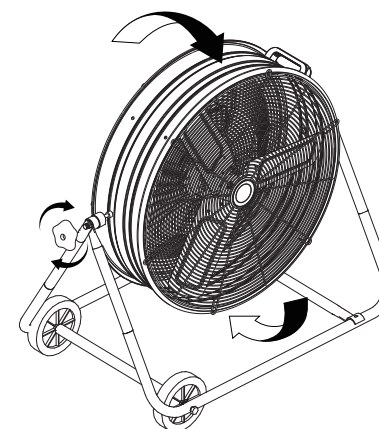


Figure B

STORAGE & MAINTENANCE GUIDELINES

1. Turn the control OFF and unplug the fan before cleaning.
2. Use only a soft damp cloth to clean the fan.
3. Do not place the fan in water and never allow water to drip into the Motor Housing.
4. Do not use gasoline, paint thinner or other chemicals to clean the fan.
5. To clean the fan blade, remove the front grill and wipe the blade and grills.
6. Store the fan in its original box or cover the fan to protect it from dust.
7. Store it in a cool and dry place.

WARRANTY

MASTER CHOICE warrants this product against defects in materials and/or workmanship under normal use for a period of ONE YEAR from the date of purchase by the original purchaser ("Warranty Period"). If a defect arises and a valid claim is received within the Warranty Period, at its option, MASTER CHOICE will either 1) repair the defect at no charge, using new or refurbished replacement parts, or 2) replace the product with a new product that is at least functionally equivalent to the original product, or provide a store credit in the amount of the purchase price of the original product. A replacement product or part, including a user-installable part installed in accordance with instructions provided by MASTER CHOICE, assumes the remaining warranty of the original product. When a product or part is exchanged, any replacement item becomes your property and the replaced item becomes MASTER CHOICE's property. When a store credit is given, the original product must be returned to MASTER CHOICE and becomes MASTER CHOICE's property. To obtain warranty service, e-mail MASTER CHOICE Limited Warranty Service at **masterchoice@afterservice.vip**. Please be prepared to describe the product that needs service and the nature of the problem.

This warranty does not apply to:

a) damage caused by failure to follow instructions relating to product' use or the installation of components; b) damage caused by accident, abuse, misuse, fire, floods, earthquake, or other external causes; c) damage caused by service performed by anyone who is not a representative of MASTER CHOICE; d) accessories used in conjunction with a covered product; e) a product or part that has been modified to alter functionality or capability; f) items intended to be periodically replaced by the purchaser during the normal life of the product including, without limitation, batteries or light bulbs; g) any product sold "as is" including, without limitation, floor demonstration models and refurbished items; or h) a product that is used commercially or for a commercial purpose.

CONTACT US

Thank you for choosing MASTER CHOICE product.

For any questions about your product or honor your warranty, please try the following methods to get in touch with us:

1. Scan the QR code below;
2. Write us at [masterchoice@afterservice.vip];
3. Call us at +1 (855) 620 5858.

Our customer service time will respond ASAP within 24 hours!

Get 24/7 Assistance at



Use camera or QR scanner to scan
<https://masterchoice.afterservice.vip>
Call: +1 (855) 620 5858 (US Toll-free)
Email: masterchoice@afterservice.vip

Questions or Problems?

Tell us

We are here
to help with
our lifetime professional
100% satisfied service
within 24 hrs.