

TECHNICAL DATA SHEET

MODEL NO.	AMPS	HP	kW	NET WT.		VOLT	FREQ.
				lbs.	kg		
120R-200T	10/8	2	1.5	128	58	208-240 / 208-230	60/50

NOTES:


1. PRESSURE SWITCH SET TO CUT-IN AT 75 PSI & CUT-OUT AT 125 PSI.
2. PRODUCT PERFORMANCE MAY VARY $\pm 10\%$ IN STANDARD PRODUCTION.
3. TECHNICAL DATA SUBJECT TO CHANGE WITHOUT NOTICE.
4. ALL DIMENSIONS ARE FOR REFERENCE ONLY.
5. FOR INDOOR USE ONLY
6. PRESSURE SWITCH SETTINGS ADJUSTABLE UP TO 125 PSI.

SOUND LEVEL 83 dB(A) / 1m


NORMAL AMBIENT 5-40 °C / 40-104 °F

RELATIVE HUMIDITY 20-80% NON CONDENSING



ENVIRONMENT CLEAN / DUST FREE

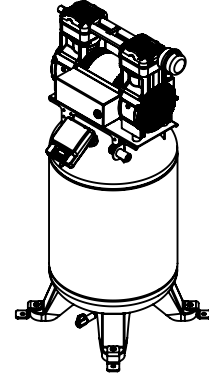

PRODUCT PERFORMANCE:

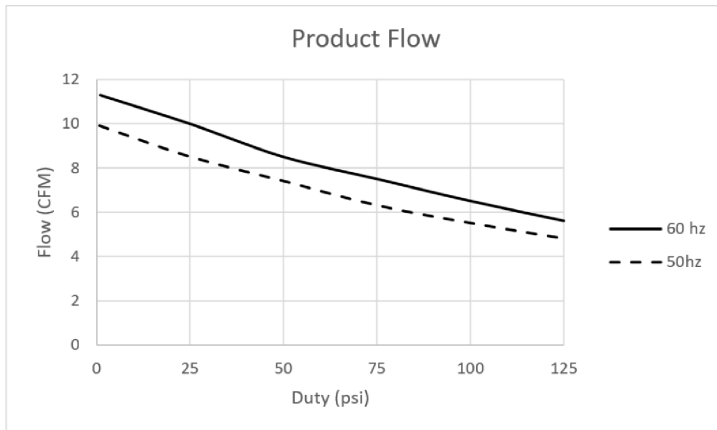

PRODUCT DIMENSIONS:

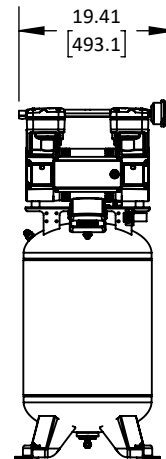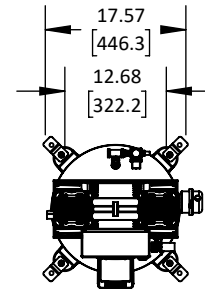

Pressure (psi)	60 Hz 30 Minute Charge Capacity (gallons)	50 Hz 30 Minute Charge Capacity (gallons)
8	5189	4579
10	4216	3626
12	3476	2992
14	2957	2558
16	2565	2219
18	2259	1947
20	2010	1728
22	1823	1558
24	1668	1428
26	1520	1299
28	1402	1197
30	1299	1111
32	1212	1035
34	1126	966
36	1063	907
38	992	854
40	940	804

