

# Type LPC-24 In-Line Fuse Holder 5 x 20mm Fuses



www.optifuse.com

(619) 593-5050

## Ratings:

**Fuse Type:** 5 x 20mm

**Electrical Rating:** 20A 32 VDC

20A 250 VAC

\*Only AC voltage is UL Recognized

**Body and Cap:** Phenolic (UL Flame: 94V-1)

**Contacts:** Nickel Plated Brass

**Cap:** Bayonet Cap

**Wire Sizes:** #12 AWG

**Wire Colors:** Red

**Body colors:** Black

**Wire Length:** Loop – 6.3 inches (160mm)

**Operation Temperature:** -30~+65°C


## Part number

**LPC-24B-12R**

## Agency Standards and Listings:



## Mechanical Dimensions: Inches [mm]

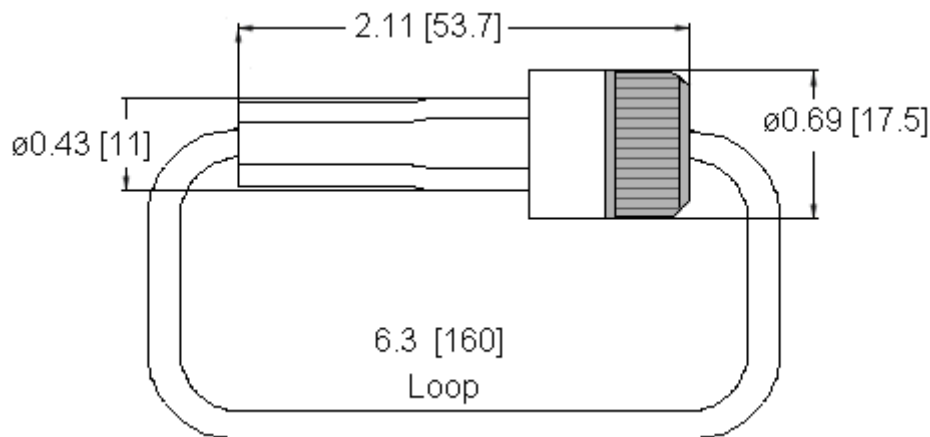

## Warning:



- Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.
- Avoid contact of device with chemical solvent. Prolonged contact may damage the device performance.
- Not designed for prolonged liquid exposure or submersible applications.

Note: All specifications subject to change without notice.

Rev D 10/2025 - Page:1/1  
Code S02-01H