
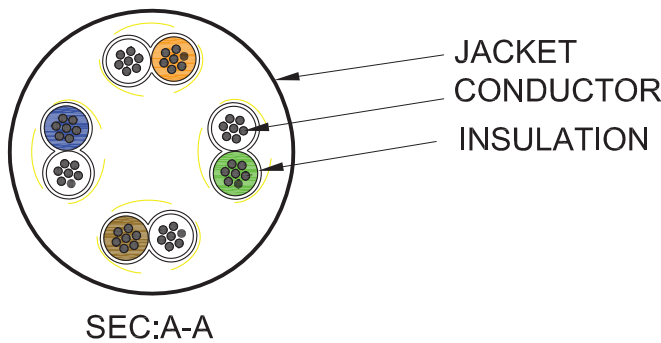


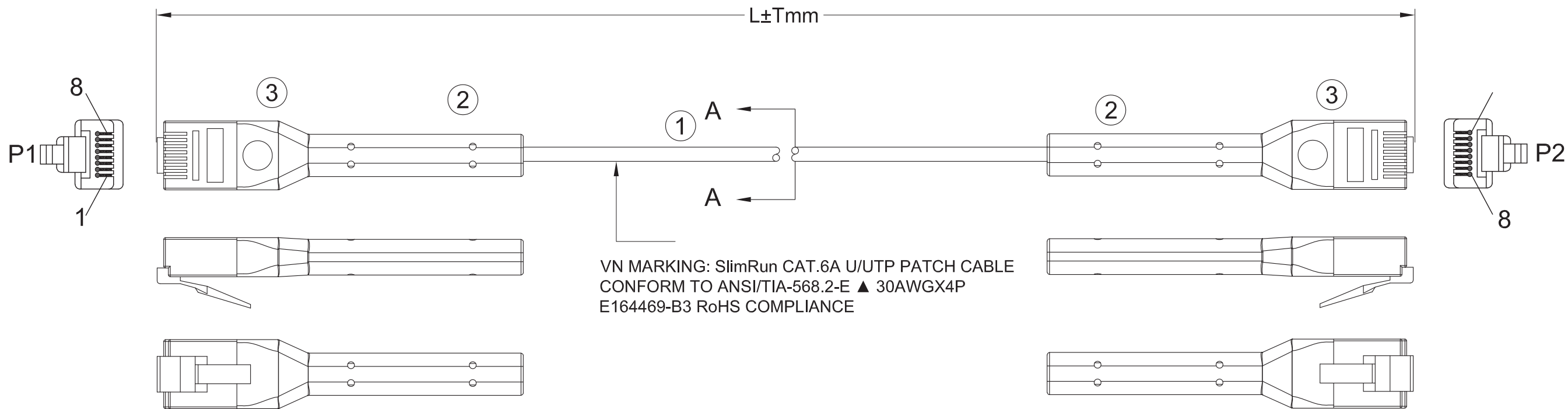

NOTE:
1.ELECTRICAL TEST:
<1> 100% OPEN SHORT & MISS WIRE TEST.
<2> FLUKE CHANNEL LEVEL 1DB↑
<3> CONDUCTOR RESISTANCE: $L \leq 10M$ 10ΩMAX
 $10 < L \leq 20M$ 15ΩMAX
 $20 < L \leq 40M$ 25ΩMAX

Conductor		Bare Copper 30AWG (7/0.10±0.008mmBC)*4P
INSULATION		Thickness:MIN at any point:0.2mm MAX AVG:0.3mm Diameter:0.50±0.06mm
Jacket	PVC	Thickness: MIN at any point:0.50mm MAX AVG:0.60mm Diameter:3.0±0.2MM

3	RJ45 PLUG	RJ45 PLUG: 8P8C 50U" GOLD PLATED TWO-PIECE PLUG.		
2	MOLDED	PVC MOLDED BOOT.		
1	CABLE	CAT6A UTP 4P/30AWG(7/0.10±0.008MM BC) OD=3.0±0.20MM CM PVC JACKET		
NO.	PART NAME	SPECIFICATION DESCRIPTION	QTY	UNIT

orange 2 white/orange	green 3 white/green
blue 1 white/blue	brown 4 white/brown

PINOUT			
PA/R	P1(T568B)	WIRE	P2(T568B)
2	1	WHT/ORG	1
	2	ORG	2
3	3	WHT/GRN	3
	6	GRN	6
1	4	BLU	4
	5	WHT/BLU	5
4	7	WHT/BRN	7
	8	BRN	8



DESCRIPTION : Monoprice™ Cat6A Ethernet Patch Cable - Bendable UTP 30AWG		
PID # : 49077 - 49151		
DATE :	UNIT : FT / IN / MM	FILE NAME:

RoHS COMPLIANT	REVISION INFORMATION		
	Rev.	Rev. Date	Brief Description

PID	Length	Color
49077	6“(0.5FT)	GRAY
49078	12“(1FT)	GRAY
49079	24“(2FT)	GRAY
49080	36“(3FT)	GRAY
49081	60“(5FT)	GRAY
49082	84“(7FT)	GRAY
49083	120“(10FT)	GRAY
49084	168“(14FT)	GRAY
49085	240“(20FT)	GRAY
49086	6“(0.5FT)	GREEN
49087	12“(1FT)	GREEN
49088	24“(2FT)	GREEN
49089	36“(3FT)	GREEN
49090	60“(5FT)	GREEN
49091	84“(7FT)	GREEN
49092	120“(10FT)	GREEN

49093	168“(14FT)	GREEN
49094	240“(20FT)	GREEN
49095	6“(0.5FT)	ORANGE
49096	12“(1FT)	ORANGE
49097	24“(2FT)	ORANGE
49098	36“(3FT)	ORANGE
49099	60“(5FT)	ORANGE
49100	84“(7FT)	ORANGE
49102	120“(10FT)	ORANGE
49104	168“(14FT)	ORANGE
49105	240“(20FT)	ORANGE
49106	6“(0.5FT)	RED
49107	12“(1FT)	RED
49108	24“(2FT)	RED
49109	36“(3FT)	RED
49110	60“(5FT)	RED
49111	84“(7FT)	RED

49112	120“(10FT)	RED
49113	168“(14FT)	RED
49114	240“(20FT)	RED
49116	6“(0.5FT)	YELLOW
49117	12“(1FT)	YELLOW
49118	24“(2FT)	YELLOW
49119	36“(3FT)	YELLOW
49120	60“(5FT)	YELLOW
49121	84“(7FT)	YELLOW
49122	120“(10FT)	YELLOW
49123	168“(14FT)	YELLOW
49124	240“(20FT)	YELLOW
49125	6“(0.5FT)	BLACK
49126	12“(1FT)	BLACK
49127	24“(2FT)	BLACK
49128	36“(3FT)	BLACK
49129	60“(5FT)	BLACK

49130	84“(7FT)	BLACK
49131	120“(10FT)	BLACK
49132	168“(14FT)	BLACK
49133	240“(20FT)	BLACK
49134	6“(0.5FT)	BLUE
49135	12“(1FT)	BLUE
49136	24“(2FT)	BLUE
49137	36“(3FT)	BLUE
49138	60“(5FT)	BLUE
49139	84“(7FT)	BLUE
49140	120“(10FT)	BLUE
49141	168“(14FT)	BLUE
49142	240“(20FT)	BLUE
49143	6“(0.5FT)	WHITE
49144	12“(1FT)	WHITE
49145	24“(2FT)	WHITE
49146	36“(3FT)	WHITE

49147	60“(5FT)	WHITE
49148	84“(7FT)	WHITE
49149	120“(10FT)	WHITE
49150	168“(14FT)	WHITE
49151	240“(20FT)	WHITE

NO.	PART NAME	SPECIFICATION DESCRIPTION	QTY	UNIT



DESCRIPTION :
Monoprice™ Cat6A Ethernet Patch Cable - Bendable UTP 30AWG

PID # :
49077 - 49151

DATE :UNIT :
FT / IN / MM

FILE NAME: