

# Steel octagon covers & accessories

## ADJUSTABLE BAR HANGERS

UL LISTED

### Features:

- Holding prong holds box in place for nailing
- Design resists bending and twisting
- Locking tabs to hold bar in position



TP356




TP352


Cat. #	Stud spacing	Fan rated	16" fan weight (lbs.)	24" fan weight (lbs.)	Fixture rated	16" fixture weight (lbs.)	24" fixture weight (lbs.)	Unit qty.	Wt. lbs. per 100
TP356	16"	No	-	-	Yes	50	-	50	41.0
TP352	16" - 24"	Yes	70	70	Yes	90	50	50	72.0

## 4" OCTAGON BOX COVERS – CUBIC CAPACITY (SEE BELOW)

UL LISTED

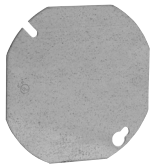


TP322, TP853<sup>B</sup>

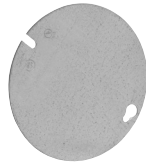


TP323




TP326, TP331,  
TP332, TP333

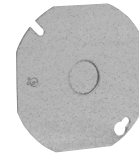


TP328

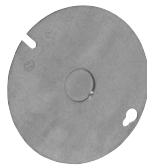


TP329

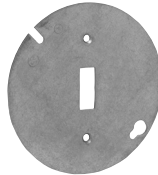

TP335

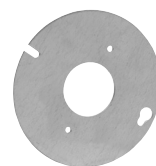

TP334

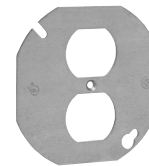

TP336

Cat. #	Description	Capacity cu. in.	Unit qty.	Wt. lbs. per 100
TP322 <sup>H</sup>	Flat blank, octagon shape	-	50	22
TP322RED <sup>H</sup>	Flat blank, octagon shape	-	50	22
TP323 <sup>H</sup>	Flat blank, round shape	-	50	24
TP333 <sup>C</sup>	Raised 1", open with ears 2 <sup>3</sup> / <sub>4</sub> "	7.8	25	25
TP332 <sup>C</sup>	Raised 1/2", open with ears 2 <sup>3</sup> / <sub>4</sub> "	3.0	25	20
TP326	Raised 5/8", open with ears 2 <sup>3</sup> / <sub>4</sub> "	3.8	50	20
TP331 <sup>C</sup>	Raised 3/4", open with ears 2 <sup>3</sup> / <sub>4</sub> "	5.8	25	25
TP328 <sup>H</sup>	Flat with 1/2" KO, octagon shape	-	50	22
TP329 <sup>H</sup>	Flat with 1/2" KO, round shape	-	50	24
TP335	Flat, for toggle switch	-	50	23
TP334 <sup>D</sup>	Flat, single receptacle 1 <sup>13</sup> / <sub>32</sub> "	-	50	21
TP336	Flat, for duplex receptacle	-	50	18

### Air plenum

TP853 <sup>B</sup> <sup>D</sup>	Flat, blank with PVC gasket	-	50	24
---------------------------------	-----------------------------	---	----	----

<sup>B</sup> For air plenum (no mounting holes) - not UL Listed.

<sup>C</sup> cUL Listed.

<sup>D</sup> Not UL Listed.

<sup>H</sup> CSA certified.