


LIGHTING CONTACTORS

Type PM - LC & LCL

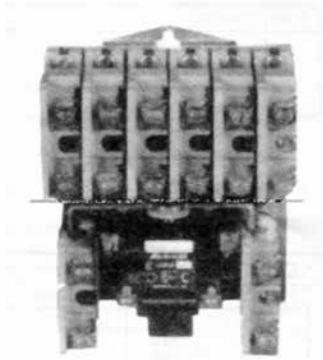

Typical 30 Ampere
Mechanically Held Lighting
Contactor, 8-Pole

* Notes: Only the KLC-33A (N.O.) and KLC-34A (N.C.) can be located on the bottom of the contactor beside the coil. All other contacts are above.



Typical 30 Ampere
Electrically Held Lighting
Contactor, 8-Pole

Lighting Contactors - LC & LCL 30 Ampere - Bulletin 7707LC

			Electrically Held - 30 Ampere			Mechanically Held - 30 Ampere		
Poles	N.O.	N.C.	NEMA Type 1		Open	NEMA Type 1		Open
			General Purpose	Dim.	Catalog No.	General Purpose	Dim.	Catalog No.
2	2	0	LC30A0020 - *	A	LC30U0020 - *	LCL30A0020 - *	B	LCL30U0020 -
2	1	1	LC30A0011 - *	A	LC30U0011 - *	LCL30A0011 - *	B	LCL30U0011 -
3	3	0	LC30A0030 - *	A	LC30U0030 - *	LCL30A0030 - *	B	LCL30U0030 -
3	2	1	LC30A0021 - *	A	LC30U0021 - *	LCL30A0021 - *	B	LCL30U0021 -
3	1	2	LC30A0012 - *	A	LC30U0012 - *	LCL30A0012 - *	B	LCL30U0012 -
4	4	0	LC30A0040 - *	A	LC30U0040 - *	LCL30A0040 - *	B	LCL30U0040 -
4	3	1	LC30A0031 - *	A	LC30U0031 - *	LCL30A0031 - *	B	LCL30U0031 -
4	2	2	LC30A0022 - *	A	LC30U0022 - *	LCL30A0022 - *	B	LCL30U0022 -
6	6	0	LC30A0060 - *	A	LC30U0060 - *	LCL30A0060 - *	C	LCL30U0060 -
6	5	1	LC30A0051 - *	A	LC30U0051 - *	LCL30A0051 - *	C	LCL30U0051 -
6	4	2	LC30A0042 - *	A	LC30U0042 - *	LCL30A0042 - *	C	LCL30U0042 -
6	3	3	LC30A0033 - *	A	LC30U0033 - *	LCL30A0033 - *	C	LCL30U0033 -
8	8	0	LC30A0080 - *	B	LC30U0080 - *	LCL30A0080 - *	C	LCL30U0080 -
8	7	1	LC30A0071 - *	B	LC30U0071 - *	LCL30A0071 - *	C	LCL30U0071 -
8	6	2	LC30A0062 - *	B	LC30U0062 - *	LCL30A0062 - *	C	LCL30U0062 -
8	5	3	LC30A0053 - *	B	LC30U0053 - *	LCL30A0053 - *	C	LCL30U0053 -
8	4	4	LC30A0044 - *	B	LC30U0044 - *	LCL30A0044 - *	C	LCL30U0044 -

Factory Modifications - NEMA Type 1

Form	Description
B	3 position selector switch
K	2 position selector switch
C	On/Off Pushbuttons - uses one pole
	space for holding circuit.

Contact Kits - Discount Schedule JC 55

Type of Operation	Type of Contact	Operating Rod Color	N.O. or N.C. Contacts	Kit Catalog No.	Location
Non-Overlap	Anti-Weld	White	1-NO	KLC-31A	Top
Non-Overlap	Anti-Weld	White	1-NC	KLC-32A	Top
Non-Overlap	Anti-Weld	White	1-NO	KLC-33A	*Bottom
Non-Overlap	Anti-Weld	Red	1-NO/1-NC	KLCA-2	Top
Overlapping	Std. Silver	Orange	1-NO/1-NC	KPMA-21	Top
Non-Overlap	Anti-Weld	Green	2-NO	KLCF-2	Top
Non-Overlap	Anti-Weld	White	1-NC	KLC-34A	*Bottom

Accessories

- Enclosures - NEMA 1 and NEMA 3R - see Page L6
- * See note at top of page for location of contacts

Ordering Information

- Use complete catalog number. Replace the (*) with the suffix from Coil Table.
- For a NEMA 3R, (2 to 8 Poles Only) replace the "A" or "U" with an "R".
Example: LCL20 R 0040
- For cover mounted operators, replace letter "O" with form letter.
Example: 3 Pos. sel. sw., LC30A B 044 -*

Coil Table

60 Hz Voltage	Suffix	DC Voltage	Suffix
24	-96	24	-024
120	-76	120	-120
208	-86	240	-240
240	-26	12	-012
277	-277	32	-032
480	-46	64	-064
600	-56		