

**NE9™**

LED Neon Rope Light



Beyond LED Technology's newest NE9 flexible Neon Rope Lights are the highest quality rope light in the market. Swap traditional neon glass tubes for these durable, flexible LED neon strip lights & stand out from the rest. Drawing from minimal power, these strips produce a continuous line of striking single-color or white neon light. Shatterproof and watertight, they are rated for use outdoors and in damp locations. A straight power cord & a pigtail connector are included for simple plug-and-play installation. Designed with a sleek jacket housing, NE9 Rope is ideal for enhancing the overall appearance of commercial buildings.


Product Features

- High Brightness Epistar Led Chips
- Each single color 50ft Roll includes (2) power cords, (2) two pin joining connectors, (2) End Caps, (100) pcs mounting clips
- RGB rope also includes controller and remote.
- Daisy Chain upto 150ft per one AC Power supply
- Durable PVC housing allows indoor & outdoor installation
- Cuttable every 20 inches
- IP67 Rated
- ETL Listed
- 2 Year warranty

LED Neon Rope Light



SKU	WATT	INPUT VOLTAGE	LIGHT SPREAD	LENGTH	COLOR	LED BRAND	IP RATING	CERTIFICATIONS
153704	3.28 W/FT	120V	120°	50ft/Roll	White	Epistar	IP67	ETL
153705	3.28 W/FT	120V	120°	50ft/Roll	Yellow	Epistar	IP67	ETL
153706	3.28 W/FT	120V	120°	50ft/Roll	Red	Epistar	IP67	ETL
153707	3.28 W/FT	120V	120°	50ft/Roll	Blue	Epistar	IP67	ETL
153712	3.28 W/FT	120V	120°	50ft/Roll	RGB	Epistar	IP67	ETL

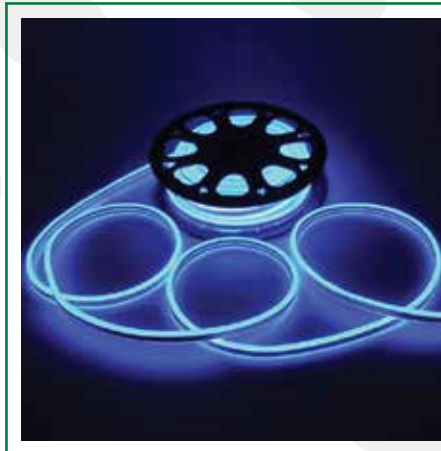




NE9™

LED Neon Rope Light

Specifications (White / Yellow / Red / Blue)

Parameter	Description	Value
General Performance	Wattage	3.28 W/FT
	Color Available	White / Yellow / Red / Blue
	LM / LED	26-28Lm each LED
	Input Voltage	120V
	Frequency	50/60Hz
	Power Factor	>0.93
	Light Spread	120°
	Operating Temperature	-15°C to +40°C
	Power Per Meter	8-10W Per meter
	LED Brand	Epistar
	LED Type	SMD2835
	LED Power	0.2W Each
	PVC Material	Anti-UV PVC 4 to 5 Grade
	PVC Color	Milky PVC
	PCB	White color 8MM PVC
	LED Qty.	120 Pcs LED per meter
	IP Rating	IP67
	Warranty	2 Years warranty

Dimension

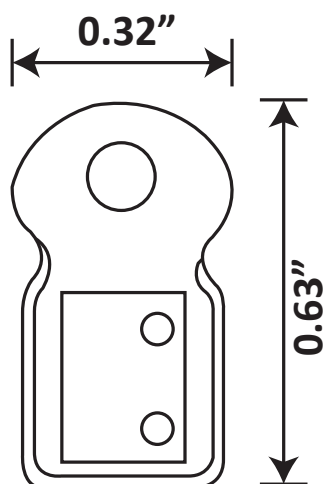




Specifications (RGB)

Parameter	Description	Value
General Performance	Wattage	3.28 W/FT
	Color Available	RGB
	LM / LED	18-20lm each LED
	Input Voltage	120V
	Frequency	50/60Hz
	Power Factor	>0.93
	Light Spread	120°
	Operating Temperature	-15°C to +40°C
	Power Per Meter	7-9W Per meter
	LED Brand	Epistar
	LED Type	SMD5050 3 Chips
	LED Power	0.2W Each
	PVC Material	Anti-UV PVC 4 to 5 Grade
	PVC Color	Milky PVC
	PCB	White color 8MM PVC
	LED Qty.	72 Pcs LED per meter
	IP Rating	IP67
	Warranty	2 Years warranty

Dimension

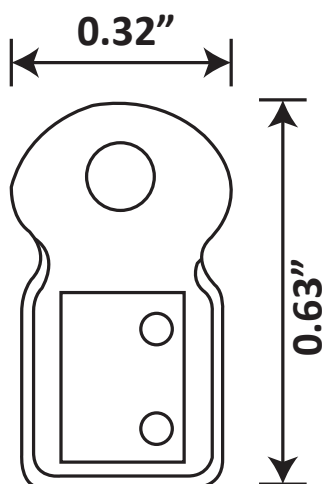



NE9™

LED Neon Rope Light

Packaging

Role Size	Box Dimension	Gross Weight
50 Meters Per Roll	13.38" x 13.38" x 13.77"	33.06LBS
25 Meters Per Roll	13.38" x 13.38" x 5.90"	17.63LBS

Application Images



his zaghi

NE9™

LED Neon Rope Light



Application Images



LED NEON ROPE LIGHT



NE9™

LED Neon Rope Light

Application Images



Warranty

This product is covered under a 2-year warranty. For complete warranty details, [Click Here.](#)