


# ISOtunes®

## PRO 3.0 LISTEN ONLY

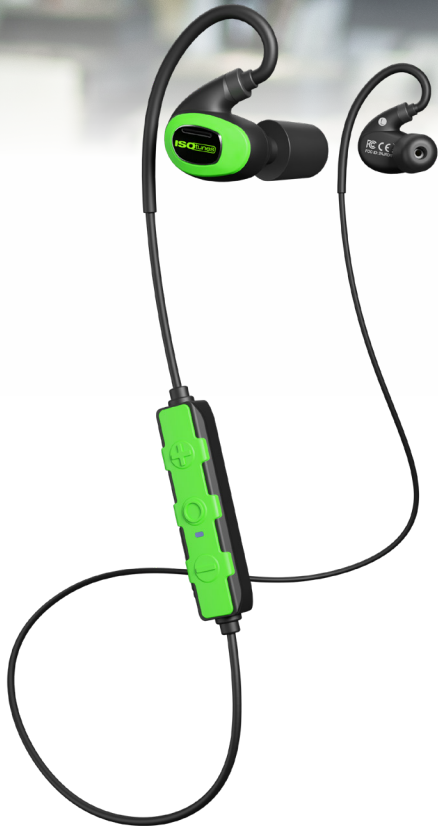

**Model:** IT-28B

**Color:** ISOtunes Green

**Bluetooth:** Yes, music only

**Product:** Noise-isolating in-ear hearing protection device with Bluetooth connectivity for music. A redesigned comfort-fit earhook provides added security that prevents the earbuds from slipping. Tested to the MIL-STD-810H standard with a chrome-plated ear stem and dust, sweat, and waterproof protection. Now with a 25% longer battery life.

**Applications:** Designed for professionals that work in loud, rugged environments who rarely take off their hearing protection.

**Standards and Approvals:** This product has been tested to the ANSI S3.19-1974 standard. It also complies with FCC, CE RED, RoHS, and WEEE requirements.

**NRR = 27 dB    CSA = AL    SNR = 36 dB    AS/NZS = Class 2**

**NRR Table (Foam Eartips)**

Frequency (Hz)	125	250	500	1000	2000	3150	4000	6300	8000	NRR	CSA
Grand Mean Attenuation (dB)	30.4	29.9	35.1	37.1	35.0	37.6	42.1	46.2	45.1	<b>27</b>	<b>AL</b>
Standard Deviation (dB)	4.7	3.5	4.9	4.6	2.8	2.6	4.5	4.2	4.1		

**NRR Table (Silicone Eartips)**

Frequency (Hz)	125	250	500	1000	2000	3150	4000	6300	8000	NRR	CSA
Grand Mean Attenuation (dB)	29.3	31.6	34.0	33.3	34.7	37.2	37.6	38.5	39.2	<b>25</b>	<b>AL</b>
Standard Deviation (dB)	3.3	3.5	3.3	4.3	3.6	3.9	4.4	4.5	4.6		

# The **Next Generation** of Hearing Protection™

SNR Tables (Foam Eartips)

Frequency (Hz)	125	250	500	1000	2000	4000	8000
Mf (dB)	30.6	30.1	36.2	38.3	37.1	39.3	45.3
Sf (dB)	4.2	3.8	4.0	3.4	3.4	3.2	4.6
APVf	26.4	26.3	32.2	34.9	33.7	36.0	40.7

SNR	36
H	35
M	33
L	30

AS/NZS Table (Foam Eartips)

Frequency (Hz)	125	250	500	1000	2000	4000	8000
Means	19.5	18.1	17.3	18.4	27.8	28.5	31.8
Standard Deviation	7.4	7.7	7.7	7.3	9.0	7.9	8.3
Means - Standard Deviation	12.1	10.4	9.6	11.1	18.8	20.6	23.5

Class	2
SLC(80)	15

AS/NZS Table (Silicone Eartips)

Frequency (Hz)	125	250	500	1000	2000	4000	8000
Means	9.5	10.5	8.2	16.1	21.6	18.5	20.9
Standard Deviation	4.8	6.1	3.9	4.8	3.1	5.4	5.8
Means - Standard Deviation	4.7	4.4	4.3	11.3	18.5	13.1	15.1

Class	1
SLC(80)	12

## TECHNICAL SPECIFICATIONS

### FEATURES:

- **SafeMax™ Technology** delivers exceptional audio quality while limiting the volume output to 85 dB
- **Redesigned Earhooks** flex to adapt for a custom fit while standing up to prolonged wear and tear
- **Ultimate Durability** with an IP67 rating and MIL-STD-810H standard testing to fully protect against dust, sweat, water, and impacts
- **High-Fidelity Audio Experience** from custom-tuned, full range dynamic drivers
- **TPU-Constructed Controller Buttons** withstand contact exposure to oils, solvents, and other residue
- **Reinforced Cables** withstand bending, twisting, and stretching for long-lasting reliability

### ACCESSORIES:

- 4 pairs of TRILOGY™ Tall Foam eartips in 4 sizes (XS, S, M, L)
- 1 zippered rigid case
- USB-C charging cable
- Replacement accessories are available

# TECHNICAL SPECIFICATIONS CONTINUED

## BLUETOOTH:

- **Version:** 5.4
  - **Profiles Supported:** HSP, HFP, A2DP, AVRCP, LC3
  - **Range:** Up to 10 meters / 30 feet
  - Dual Connect with two Bluetooth devices at once
  - Supports Bluetooth battery level indicator
- \* Only use a charge of 5 volts/1 amp output maximum. Using a charger higher than 5 volts/1 amp output could be dangerous and may damage the headset.
- \*\* Times may vary depending on usage.

## BATTERY:

- Built-in rechargeable 3.7 volt lithium-ion battery
- **Input:** USB-C
- **Charging Voltage:** 5 volts DC\*
- **Charging Time:** 2 - 3 hours\*\*
- **Music Playback Time:** 20 hours\*\*
- **Standby Time:** 270 hours\*\*
- **Number of Batteries:** 2
- **Earbud Battery Weight:** 1.7 g each (3.4 g total)
- **Earbud Battery Capacity:** 75 mAh or 0.2775 Wh each

## SHIPPING:

- **Product Weight:** 16.5 grams
- **Packaged Dimensions:** 12.07 x 11.43 x 5.72 cm
- **Packaged Weight:** 199 grams
- **Inner Carton Quantity:** 10 units
- **Inner Carton Dimensions:** 30 x 25 x 15 cm
- **Inner Carton Weight:** 2.5 kg
- **Outer Carton Quantity:** 4 inner cartons (40 units)
- **Outer Carton Dimensions:** 53 x 32 x 33 cm
- **Outer Carton Weight:** 9.96 kg

**Important Notice:** Haven Technologies does not accept liability of any kind, be it direct or consequential (including, but not limited to, loss of profits, business and/or goodwill) arising from reliance upon any information herein provided by Haven Technologies. The user is responsible for determining the suitability of the products for their intended use. Nothing in this statement will be deemed to exclude or restrict Haven Technologies liability for death or personal injury arising from its negligence.

**Warranty:** The warranty does not cover any damage caused by neglected maintenance or careless handling. For more information on maintenance, please see the user instruction. For complete warranty conditions, contact your dealer or local Haven Technologies Office.