
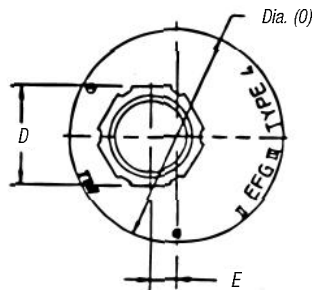


Hubs and Bulkhead Fittings

Offset Reducers


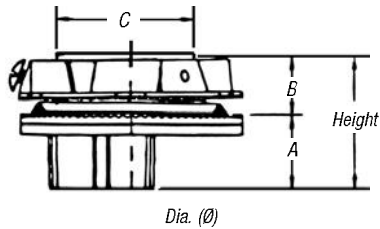


CAT. NO.	TRADE SIZE	HEIGHT	DIA. (Ø)	(IN.)				
				A DIA.	B	C	D	E
H150-TB075ORGR	1½"–¾"	1 ²⁹ / ₃₂ "	2¾	1 ¹⁵ / ₁₆	²³ / ₃₂	1 ²⁹ / ₃₂	1 ⁹ / ₃₂	1 ¹¹ / ₃₂
H150-TB100ORGR	1 ³ / ₃₂ "–1"	1 ²⁵ / ₃₂ "	2¾	1 ¹ / ₁₆	²³ / ₃₂	1 ²⁹ / ₃₂	1 ⁹ / ₁₆	⁷ / ₃₂
H150-TB125ORGR	1 ³ / ₃₂ "–1¼"	1 ²⁵ / ₃₂ "	2¾	1 ¹ / ₁₆	²³ / ₃₂	1 ²⁹ / ₃₂	1 ¹ / ₈	¹ / ₃₂
H250-TB200ORGR	2½"–2"	2½"	3¾	1 ³ / ₁₆	¹⁵ / ₁₆	2 ²⁹ / ₃₂	2 ² / ₃₂	³ / ₃₂

Material — Offset Reducer and Locknut: Zinc or copper-free aluminum
 Insulating Throat: Thermoplastic Temp. Rating – 105° C
 Flammability Rating – 94V-0
 Sealing Ring: Nitrile (BUNA "N")

For Aluminum Offset Reducer, add suffix A.
 For Chrome-Plated Offset Reducer, add suffix CP.
 Meets NEMA sealing requirements for NEMA 3R, 4 & 13 enclosures.
 CSA Certified for hazardous locations Class II Groups E.F.G. Class III.
 UL File No. E-3060
 CSA File No. 4484

Capoffs

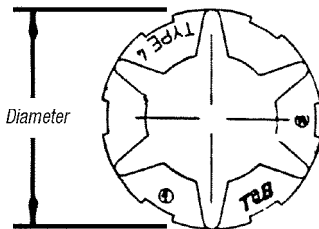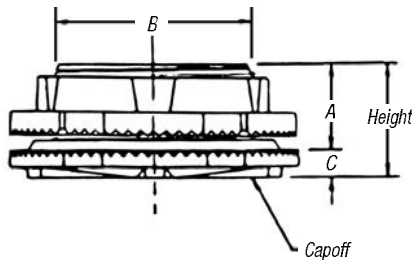

CAT. NO.	TRADE SIZE	HEIGHT	DIAMETER	(IN.)		
				A	B	C
H050CAP	½"	1 ¹³ / ₃₂ "	1 ¹ / ₁₆	¹³ / ₃₂	² / ₃₂	³ / ₁₆
H075CAP	¾"	1 ¹⁵ / ₃₂ "	1 ¹¹ / ₁₆	¹³ / ₃₂	1 ¹ / ₁₆	³ / ₁₆
H100CAP	1"	1 ¹¹ / ₁₆ "	2	1 ¹ / ₁₆	1 ¹ / ₁₆	¹ / ₄
H125CAP	1¼"	1 ²⁵ / ₃₂ "	2 ⁵ / ₈	²³ / ₃₂	1 ²¹ / ₃₂	¹ / ₄
H150CAP	1½"	1 ¹³ / ₁₆ "	2¾	²³ / ₃₂	1 ²⁹ / ₃₂	¹ / ₄
H200CAP	2"	1 ²⁷ / ₃₂ "	3¼	²³ / ₃₂	2 ³ / ₈	¹ / ₄
H250CAP	2½"	2 ³ / ₃₂ "	3¾	¹ / ₈	2 ²⁹ / ₃₂	¹ / ₄
H300CAP	3"	2 ³ / ₁₆ "	4 ³ / ₈	¹ / ₈	3 ³ / ₃₂	1 ¹¹ / ₃₂
H350CAP	3½"	2 ¹ / ₁₆ "	5	²⁹ / ₃₂	4 ¹ / ₃₂	1 ¹ / ₃₂
H400CAP	4"	2 ⁹ / ₁₆ "	5½	²⁹ / ₃₂	4 ¹ / ₂	1 ¹ / ₃₂
H500CAP	5"	2 ²³ / ₃₂ "	6 ⁷ / ₈	²⁹ / ₃₂	5 ⁹ / ₁₆	1 ¹ / ₃₂
H600CAP	6"	3"	7 ⁷ / ₈	³¹ / ₃₂	6 ⁷ / ₈	1 ¹ / ₃₂

Material — Capoff and Locknut: Zinc or copper-free aluminum
 Insulating Throat: Thermoplastic temp. rating – 105° C
 Flammability Rating – 94V-0
 Sealing Ring: Nitrile (BUNA "N")

For Aluminum Capoff, add suffix A.
 For Chrome-Plated Capoff, add suffix CP.
 Meets NEMA sealing requirements for NEMA 3R, 4 & 13 enclosures.
 CSA Certified for hazardous locations Class II Groups E.F.G. Class III.
 UL File No. E-3060
 CSA File No. 4484