



Post Office Box 97
Benton Harbor, Michigan
Ph: 269/926-6171
Fax: 269/925-8288

Product Specifications

PART NUMBER:

STD387A

REV.







A

Model Number	Motor Voltage	RPM		HP	kW	Net Wt.	
		60 cycle	50 cycle			lbs.	kg
0523-101Q-G588NDX	110-115/220-240	1725	1425	.25	0.18	30	13.6

SOUND LEVEL LESS THAN 70 dB(A)
NORMAL AMBIENT 1°C. - 40°C.
RELATIVE HUMIDITY 8% - 100% NON CONDENSING
ENVIRONMENT CLEAN DUST FREE

NOTES:

- 1) TECHNICAL DATA SUBJECT TO CHANGE WITHOUT NOTICE.
- 2) DIMENSIONS ARE FOR REFERENCE ONLY.
- 3) DASHED LINE INDICATES 50 Hz. PERFORMANCE.
SOLID LINE INDICATES 60 Hz. PERFORMANCE.

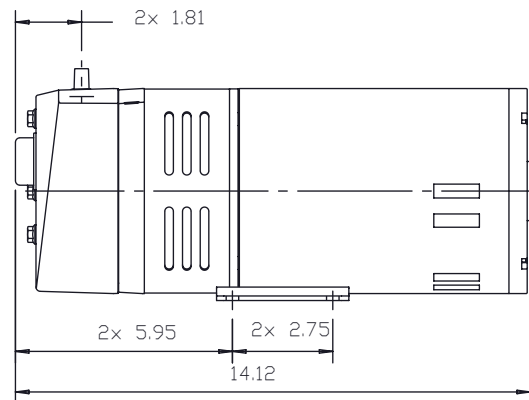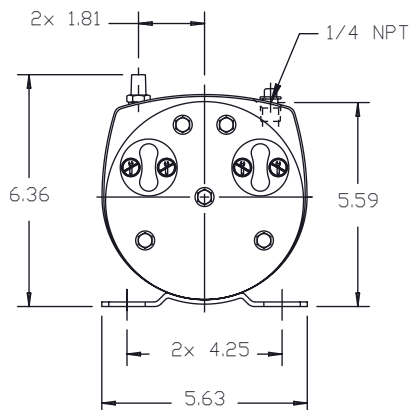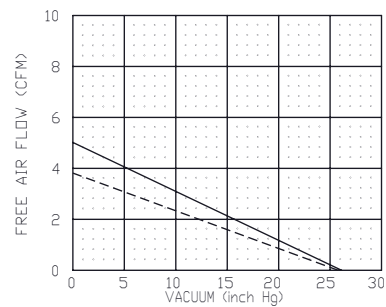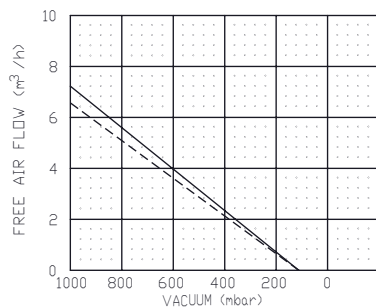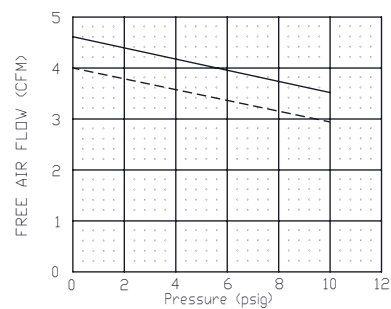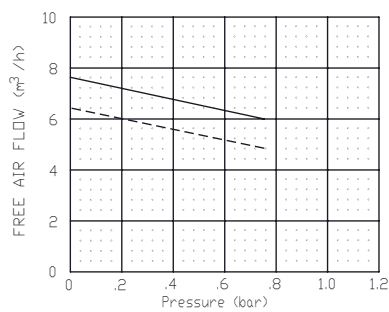

FOOT SUPPORT INCLUDED
SHIPPED UNATTACHED

