

Both Fortress and Slimduct are now available in convenient kit form.
Kit includes duct and fittings for typical mini-split installation.



lineset ducting. Simple, rugged protection.



C H O O S E F O R T R E S S O R S L I M D U C T Q U A L I T Y



Fortress® SATIN FINISH

Moderate price point. For mini-splits, high velocity and conventional split air conditioning systems.

Protects lineset, wiring and drain hose from weather, vandalism, pet and pest damage.

Snap together ducting easily accessed for repairs or replacement of the lineset.

UV and weather resistant. Will remain attractive and provide protection for many years.

Stylish. Complements any residential or commercial building. Paintable. Brush, spray or roller to match or complement custom colors.*


2 sizes. Duct & fittings are available in both LD92 (3½"), LD122 (4½")

4 color options. white, ivory, brown, gray

8' duct lengths. 6 lengths per box

17 fittings. Ensures complete flexibility of installation

*Follow paint manufacturers recommendations for vinyl products.

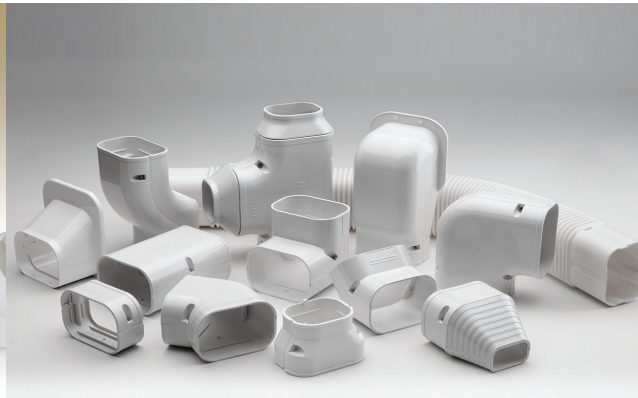

Slimduct® GLOSS FINISH

Heavy duty grade. For mini-splits, high velocity and conventional ducted air conditioning systems.

Protects lineset, wiring and drain hose from weather, vandalism, pet and pest damage.

Snap together ducting easily accessed for repairs or replacement of the lineset.

UV, weather and fire resistant with a temperature range from - 4°F to 140°F. Will remain attractive and provide protection for many years.

Stylish. Complements any residential or commercial building.

3 sizes. Duct & fittings are available in SD77 (2¾"), SD100 (3¾"), SD140 (5½")

3 color options. white, ivory, brown

78" duct lengths. 5 lengths per box

15 fittings. Ensures complete flexibility of installation

NOTE: Dark colors fade in sunlight sooner than lighter colors.

WHITE

Order code / Ref No Qty

84004 (LD92W) 6
84104 (LD122W) 6
84180 (LAD150W) 5

IVORY

Order code / Ref No Qty

84024 (LD92I) 6
84124 (LD122I) 6

BROWN

Order code / Ref No Qty

84064 (LD92B) 6
84164 (LD122B) 6

GRAY

Order code / Ref No Qty

84044 (LD92G) 6
84144 (LD122G) 6

84010 (LJ92W) 6
84110 (LJ122W) 6
84185 (LAJ150W) 2

84030 (LJ92I) 6
84130 (LJ122I) 6

84270 (LJ92B) 1
84370 (LJ122B) 1

84250 (LJ92G) 1
84350 (LJ122G) 1

84016 (LW92W) 6
84116 (LW122W) 6
84189 (LAW150W) 2

84036 (LW92I) 6
84136 (LW122I) 6

84276 (LW92B) 1
84376 (LW122B) 1

84256 (LW92G) 1
84356 (LW122G) 1

84007 (LEN92W) 6
84107 (LEN122W) 6
84184 (LAE150W) 2

84027 (LEN92I) 6
84127 (LEN122I) 6

84267 (LEN92B) 1
84367 (LEN122B) 1

84247 (LEN92G) 1
84347 (LEN122G) 1

84011 (LK92W) 6
84111 (LK122W) 6
84186 (LAK150W) 2

84031 (LK92I) 6
84131 (LK122I) 6

84271 (LK92B) 1
84371 (LK122B) 1

84251 (LK92G) 1
84351 (LK122G) 1

84014 (LP92W) 6
84114 (LP122W) 6
84187 (LHJK150W) 2

84034 (LP92I) 6
84134 (LP122I) 6

84274 (LP92B) 1
84374 (LP122B) 1

84254 (LP92G) 1
84354 (LP122G) 1

84012 (LKF92W) 6
84112 (LKF122W) 6

84032 (LKF92I) 6
84132 (LKF122I) 6

84272 (LKF92B) 1
84372 (LKF122B) 1

84252 (LKF92G) 1
84352 (LKF122G) 1

84002 (LCI92W) 6
84102 (LCI122W) 6
84183 (LAC150W) 2

84022 (LCI92I) 6
84122 (LCI122I) 6

84262 (LCI92B) 1
84362 (LCI122B) 1

84242 (LCI92G) 1
84342 (LCI122G) 1

84003 (LCO92W) 6
84103 (LCO122W) 6

84023 (LCO92I) 6
84123 (LCO122I) 6

84263 (LCO92B) 1
84363 (LCO122B) 1

84243 (LCO92G) 1
84343 (LCO122G) 1

84182 (LACM150W) 2
84181 (LAKM150W) 2

84000 (LCFI92W) 6
84100 (LCFI122W) 6

84020 (LCFI92I) 6
84120 (LCFI122I) 6

84260 (LCFI92B) 1
84360 (LCFI122B) 1

84240 (LCFI92G) 1
84340 (LCFI122G) 1

84001 (LCFO92W) 6
84101 (LCFO122W) 6

84021 (LCFO92I) 6
84121 (LCFO122I) 6

84261 (LCFO92B) 1
84361 (LCFO122B) 1

84241 (LCFO92G) 1
84341 (LCFO122G) 1

84015 (LT92W) 6
84115 (LT122W) 6
84188 (LATK150W) 2

84035 (LT92I) 6
84135 (LT122I) 6

84275 (LT92B) 1
84375 (LT122B) 1

84255 (LT92G) 1
84355 (LT122G) 1

84106 (LDR12292W) 6

84126 (LDR12292I) 6

84366 (LDR12292B) 1

84346 (LDR12292G) 1

84013 (LKS92W) 6
84113 (LKS122W) 6

84033 (LKS92I) 6
84133 (LKS122I) 6

84273 (LKS92B) 1
84373 (LKS122B) 1

84253 (LKS92G) 1
84353 (LKS122G) 1

84008 (LF92W) 6
84108 (LF122W) 6

84028 (LF92I) 6
84128 (LF122I) 6

84268 (LF92B) 1
84368 (LF122B) 1

84248 (LF92G) 1
84348 (LF122G) 1

84009 (LFJ92W) 6
84109 (LFJ122W) 6

84029 (LFJ92I) 6
84129 (LFJ122I) 6

84269 (LFJ92B) 1
84369 (LFJ122B) 1

84249 (LFJ92G) 1
84349 (LFJ122G) 1


84017 (LWF92W) 6
84117 (LWF122W) 6

84037 (LWF92I) 6
84137 (LWF122I) 6

84277 (LWF92B) 1
84377 (LWF122B) 1

84257 (LWF92G) 1
84357 (LWF122G) 1

84099 (LDC) (12 pk 50 bags)

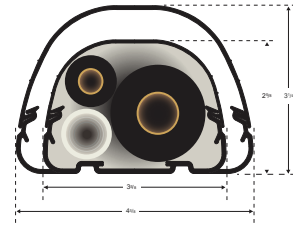**Technical Information**

Weather resistant PVC,
UV stabilized & fire resistant.
Tested to over 2,000 hours.

Temperature Range
-4°F to 140°F

**12' Wall Duct Kit**

Kit includes 12' of duct and all essential fittings to hide and protect the lineset for a typical A/C installation. Available in white, ivory, gray and brown.

LDK Kit includes:

LD – Ducting 4' Long (3)
LJ – Couplers (2)
LW – Wall Inlet (1)
LEN – End Fitting (1)
LK – 90° Flat Ell (1)

Fortress Kits:

84045 LDK92G – Gray 3½
84145 LDK122G – Gray 4½
84065 LDK92B – Brown 3½
84165 LDK122B – Brown 4½
84005 LDK92W – White 3½
84105 LDK122W – White 4½
84025 LDK92I – Ivory 3½
84125 LDK122I – Ivory 4½

