



Post Office Box 97  
 Benton Harbor, Michigan  
 Ph: 269/926-6171  
 Fax: 269/925-8288

# Product Specifications



PART NUMBER: STD327  
 REVISION: A

Model Number	RPM		HP	kW	Net Wt.	
	60 CYCLE	50 CYCLE			lbs.	kg
2567-V1	1725	1425	1.5	1,1	51	23,2

SOUND LEVEL 78 dB(A) MAX.  
 NORMAL AMBIENT 1° C. - 40° C.  
 RELATIVE HUMIDITY 8% - 100% NON CONDENSING  
 ENVIRONMENT CLEAN DUST FREE

- NOTES:  
 1. TECHNICAL DATA SUBJECT TO CHANGE WITHOUT NOTICE.  
 2. DIMENSIONS ARE FOR REFERENCE ONLY UNLESS TOLERANCED.  
 3. \* DENOTES INACTIVE.

## Product Performance (Metric U.S. Imperial)

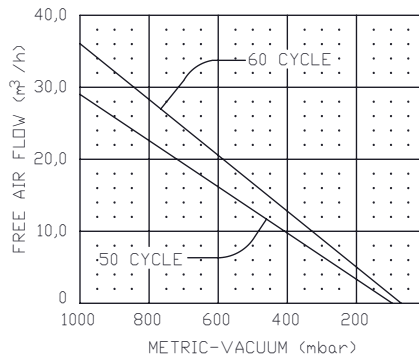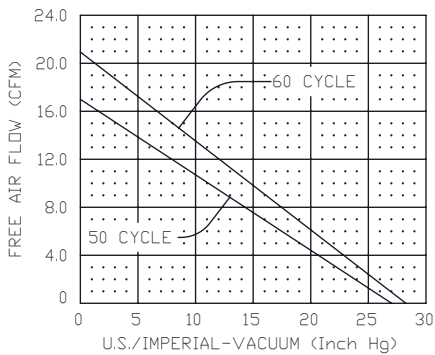

## Product Dimensions (Metric (mm) U.S. Imperial (inches))

