

Steel square covers

4¹¹/₁₆" SQUARE SURFACE COVERS – 9.0 CUBIC INCH CAPACITY

UL LISTED
CSA LISTED


1/2" RAISED



TP720



TP722

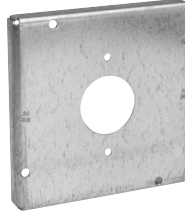

TP724, TP730,
TP736




TP726



TP728



TP732

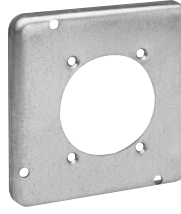

TP734



TP738



TP740

Cat. #	Description	Unit qty.	Wt. lbs. per 100
TP720	For one toggle switch	10	52
TP722	For one duplex receptacle	10	49
TP724	For one single receptacle 1 ¹³ / ₃₂ " (1.406") dia.	10	53
TP730	For one single receptacle 1 ²¹ / ₃₂ " (1.656") dia.	10	50
TP736	For one power outlet 1 ⁷ / ₆₄ " (1.734") dia.	10	51
TP726	For two toggle switches	10	52
TP728	For two duplex receptacles	10	44
TP732	For one power outlet 2 ³ / ₆₄ " (2.141") dia.	10	48
TP734	For one power outlet 2 ¹⁵ / ₃₂ " (2.469") dia.	10	45
TP738	For one ground fault interrupter	10	45
TP740	For one GFI receptacle and one toggle	25	45
TP741	For two GFI receptacles	10	43

Steel boxes