

Notebook Monitor Arm Combo Mount

Mounting Options

Notebook monitor arm combo mount includes bolt through and desk clamp mounting options

Desk Clamp

Suits desktop thicknesses of 0mm-76mm (0"-3")

Bolt Through

Suits desktop thicknesses of 12mm-40mm (0.5"-1.5")

Display Mounting Options

Suits 100mm x 100mm mounting hole pattern

Notebook Mounting Options

Support notebook up to 18"

Display weight compatibility


Max. 8kg (17.6lbs) per display

Consist of

Notebook arm
Monitor arm
Fasteners
Mounting hardware


Warranty

10 years limited

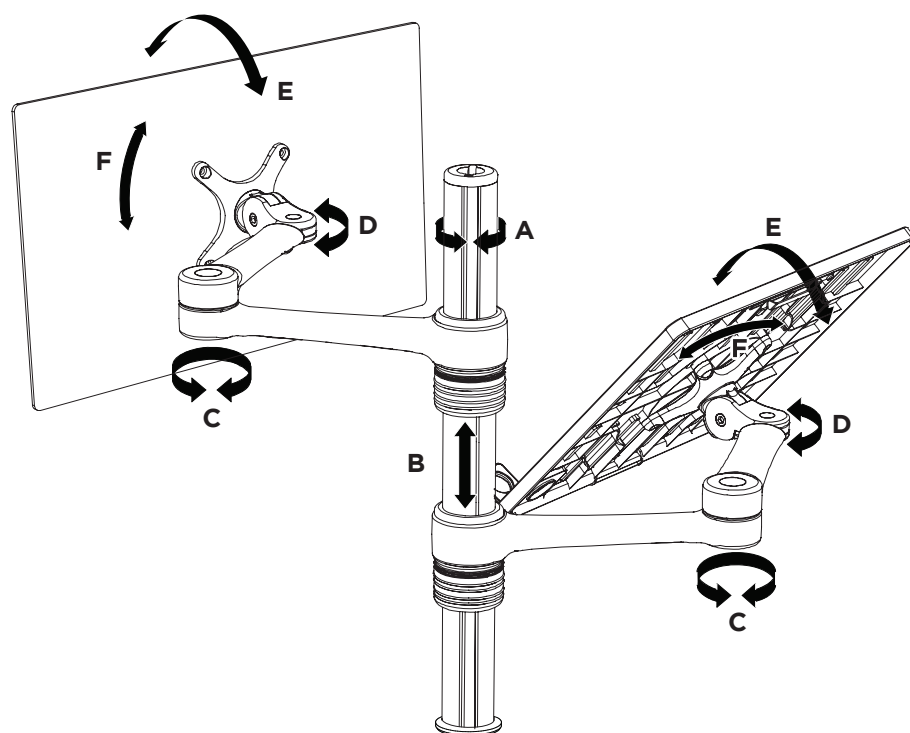


- A** 360° rotation around mounting pole/ 180° with rotation limiter
- B** 270mm (10.03") height adjustment range
- C** 360° articulation of arms
- D** 180° pan adjustment
- E** Tilt $\pm 70^\circ$ (monitor arm)
25° (notebook tray)
- F** $\pm 95^\circ$ Portrait/ landscape adjustment (monitor arm)
- G** $\pm 5^\circ$ horizontal adjustment (notebook tray)

Portrait/ Landscape

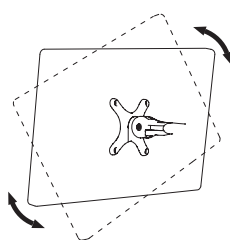


No Allen Key necessary

Tilt (Screen angle up/down)

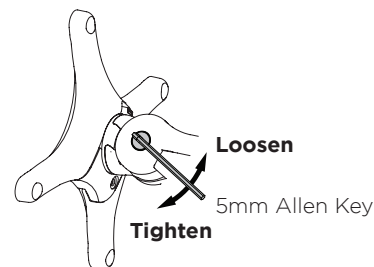


Note: Support Screen when adjusting tilt.

Pan (Screen angle left/right)

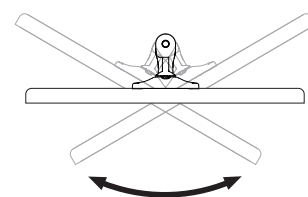


No Allen Key necessary

100mm x 100mm VESA hole pattern

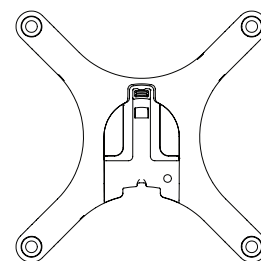

Mounting Options

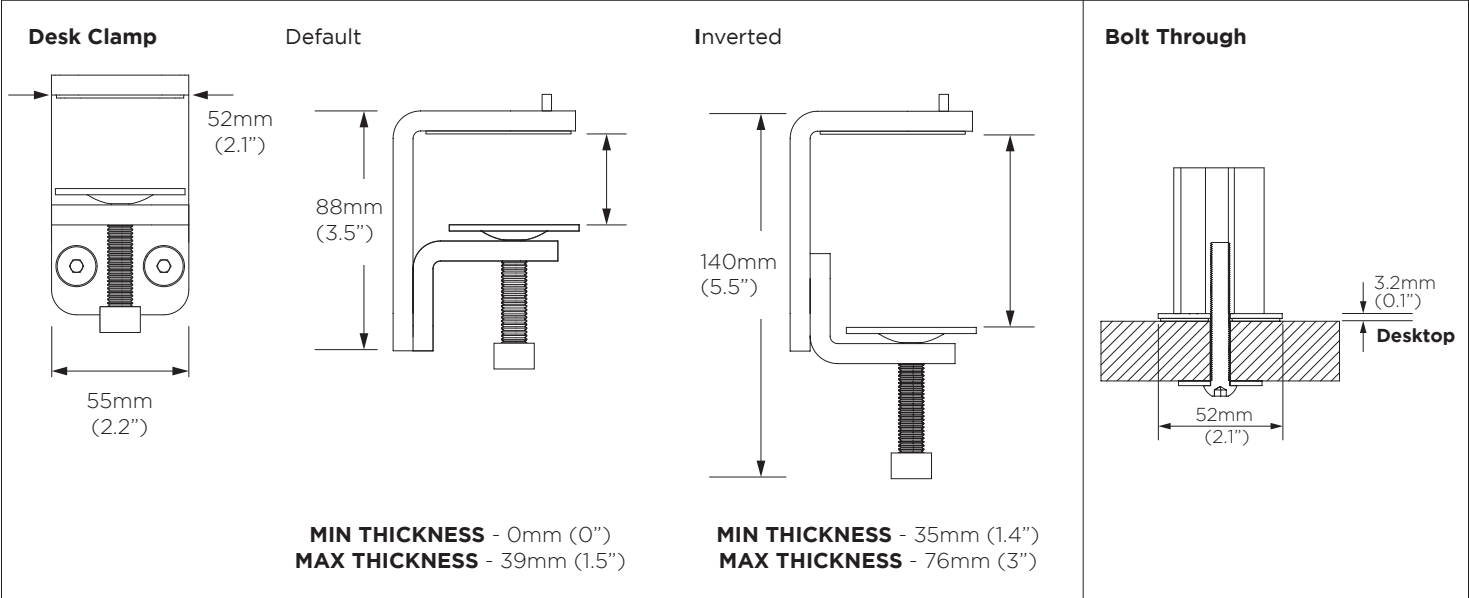

Overall Dimensions

