

Wireless HD Security kit 4+1

Making Technology Work

plustek
SECURITY

More Fast. More Far
5GHz
Go further & faster
with two antennas!



HD 720P
Digital



Wi-Fi 5GHz



Plug & Play



Push Message



Playback on Mobile


No Cabling!


No Hassles!

Simple

No complex wiring needed

Fast

Plug & play, auto pairing cameras

Safety


Support various mobile apps

Battle of the Bands: 2.4 GHz v.s. 5 GHz




Today, using the 2.4GHz wireless band is like driving during peak hours. You are stuck in traffic, waiting for webpages to load and packages to be transmit; this is because most of the wireless devices today run on this frequency.



With 5GHz frequency wireless networks, more lanes are open enabling more cars to pass through, offering relief from the overcrowding of 2.4GHz resulting in higher speed.

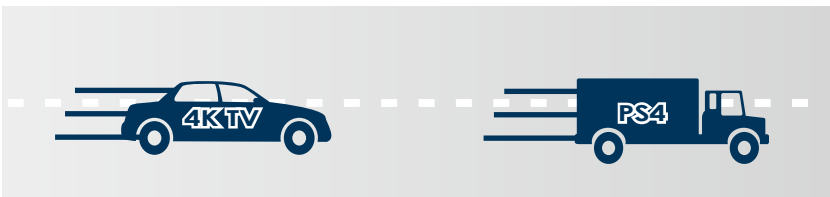

Just plug & start monitoring
with a peace of mind

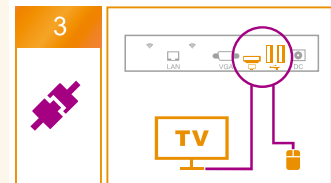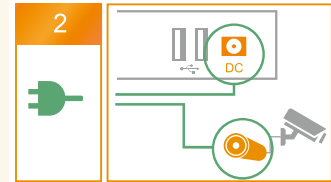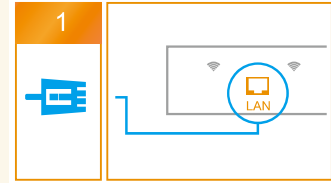

Specifications

Network Video Recorder (WiFi NVR)	Recording Cameras	4
	Recording Frame per Second (fps)	120 fps@720p, H.264
	Network Interface	IEEE 802.11 Wi-Fi (5.0GHz Mimo) , Fast Ethernet (x1, RJ-45)
	Hard Disk Drive (HDD)	1 (one) 3.5" SATA HDD *Supports up to 6TB, HDD not included
	Connectors	1 x RJ-45 Ethernet port 1 x VGA Output (max. res: 1280x960) 1 x 1080P HD Output (max. res: 1280x960) 2 x USB 2.0 (Mouse Control & Backup) 1 x DC-Jack (power-in 12V/3A)
	Dimensions	257 x 232 x 43 mm
	Net Weight	982g
Wireless Camera	Resolution	1280 x 720
	Lens	3.6mm, 6mm
	Max. Transmission Range	Up to 300ft / 100m *Based on indoor range & depending on local conditions
	Day/Night	Up to 60ft (20M)IR Night vision
	Network Interface	Wi-Fi , Fast Ethernet
	Dimensions	64 x 117 x 66 mm
General	Indoor/ Outdoor	Indoor & Outdoor Suitable, IP66 rated
	Operating Power	DC 12V
	Operating Temperature	14°F~131°F (-10°C- +55°C) Humidity (%RH): 10%-90%

G11AE-00101