


Japan Power Cord - 2-Prong Plug with Ground Wire to C13 - 1 m

Product ID: PXTJ1011M

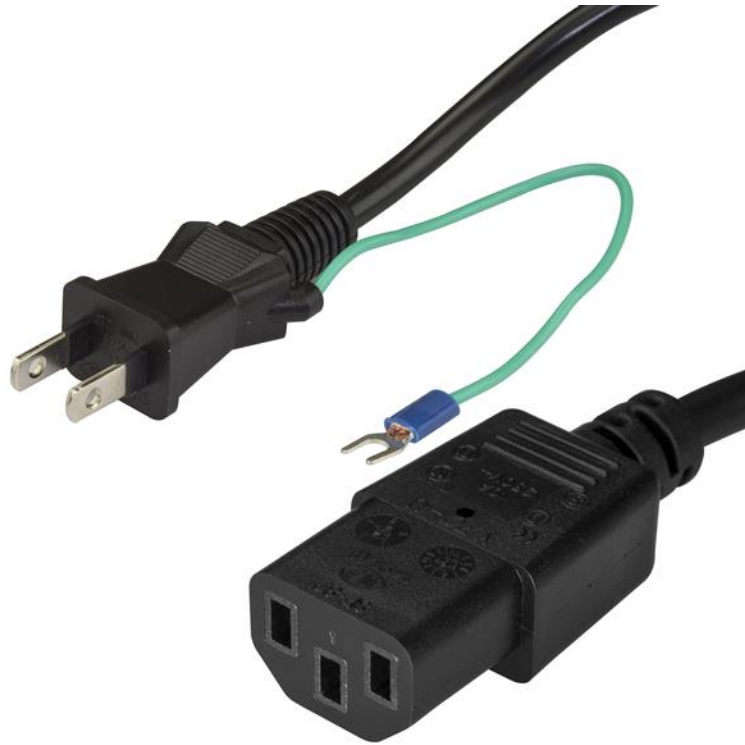

This 2-prong plug power cable with ground wire is constructed of top-quality materials, and designed to provide a durable, long-lasting power connection to your peripheral devices.

The cable is rated to carry 125V at 7A and complies with the Electrical Appliance and Material Safety Law (PSE standards).

The PXTJ1012M is backed by a StarTech.com lifetime warranty for guaranteed reliability.

Certifications, Reports and Compatibility



Applications

- Connect your computer, monitor, printer or other device to a power outlet

Features

- Rated to carry 125V at 7A
- PSE compliant
- ROHS approval
- Guaranteed reliability

Hardware	Warranty	Lifetime
	Cable Type	VCTF
	Number of Conductors	3
Connector(s)	Connector A	1 - 2P with Ground Wire Power (NEMA 1-15) Plug
	Connector B	1 - IEC 60320 C13 Power Receptacle
Power	Input Current	7 A
	Input Voltage	125 AC
Physical Characteristics	Cable Length	3.3 ft [1 m]
	Color	Black
	Connector Style	Straight
	Product Height	0.5 in [12 mm]
	Product Length	39.4 in [1000 mm]
	Product Weight	3.8 oz [109 g]
	Product Width	0.4 in [10 mm]
Wire Gauge	0.75mm ²	
Packaging Information	Shipping (Package) Weight	4.6 oz [129 g]
What's in the Box	Included in Package	1 - 2-prong plug with ground wire to C13 power cord

Product appearance and specifications are subject to change without notice.