



TROY M607 / M608 / M609

MICR Printer



Select your preferred level of security by choosing from three models including our basic MICR printer, our more advanced MICR Secure printer, or our most advanced MICR Secure Ex printer. This model is fully compatible with TROY MICR cartridges and standard HP cartridges. Fast printing and features like duplexing allow for multifunctional use in small to medium sized office environments. Enjoy HP award-winning reliability combined with optimized security from TROY.

Benefits

Streamline Your Secure Check Printing

TROY M607 / 608 / 609 MICR Printers eliminate the security risks of using preprinted check stock by allowing companies to print checks on demand. Incorporate your logo, customer data, signature, and MICR line onto the checks at the point of print. With three models, each available with three security levels, you can choose the print capacity and protection to fit your organization's needs.

Add Layers of Security

The security features of the TROY M607, M608, M609 MICR Printers, combined with TROY MICR Toner Secure, ensure each printed check is highly resistant to fraudulent alteration.

Reduce Time Consuming Processes


Simplify or eliminate chain of custody procedures with built-in tray locks and steel shielding to protect valuable check stock in the printer.



Features


ExPT™ Exact Positioning Technology

A MICR line out of alignment is one cause of rejected checks, a multi-million dollar problem for banks and companies. ExPT allows users to precisely adjust the MICR line without affecting the data file.

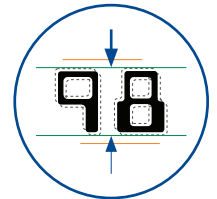

Built-In Secure Encryption and Decryption

Data security is critical in a distributed printing application. TROY's encryption/decryption technology "unlocks" and prints the data only when it is received at the TROY printer.

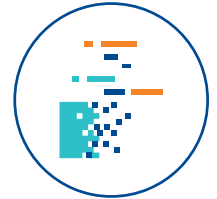

Exclusive TROYMark™ Intelligent, Anti-Tampering Technology

TROYMark is a watermark of user-defined, variable data, printed diagonally across each check. It provides state-of-the-art deterrence of fraudulent check alteration.



3-Position Printer Lock

Most businesses locate their workgroup printer in an open office environment, creating a security risk. This 3-position lock allows users to physically lock the printer's secure resources, protecting users from fraud by refusing unauthorized access.



Paper Tray Locks & Tray Shielding

Prevent unauthorized access to valuable check stock with built-in locking paper trays and steel tray shielding to prevent paper removal from the back of the printer.



TROY MICR Features	Secure Ex	Secure	MICR	M607n Specifications
TROY ExPT™ - Exact Positioning Technology	✓	✓	✓	Print Speed Black, Letter: ISO/Best Quality First Page Out Print Quality, Black Best Duty Cycle, Monthly Monthly Volume Two-Sided Printing Up to 55 ppm As fast as 5.3 sec Up to 1200 x 1200 dpi Up to 250,000 pages 5,000 - 20,000 pages Manual
Auto-Protect Font	✓	✓	✓	
Disable Jam Recovery	✓	✓	✓	
Auto Set MICR Density	✓	✓	✓	
MICR Toner Low Notification	✓	✓	✓	
Flash Memory for Storing Digital Signatures and Logos	✓	✓	✓	
Barcode Fonts U.P.C. A&E, EAN 13&8, Interleaved 2 of 5, Code 39, Code 128, Postnet	✓	✓	✓	
MICR Fonts E13-B, CMC-7, OCR A and B Convenience and Security Fonts	✓	✓	✓	
User Customizable MicroPrint Font	✓	✓	✓	
Auto Page Rotation	✓	✓	✓	
MICR Menu Administrator Password	✓	✓	✓	
MICR Quality Test Page	✓	✓	✓	
Uses Either TROY MICR or HP Standard Toner Cartridges	✓	✓	✓	
PIN-Activated Controls: Printer, MICR, Job	✓	✓	✓	
MICR Toner Sensing	✓	✓	✓	
TROY Enhanced Audit	✓	✓	✗	
MICR Line and Check Audit Trail Reporting	✓	✓	✗	
Password Protected Signatures and Logos	✓	✓	✗	
3-Position Keylock Printing Control	✓	✗	✗	
TROYMark™ Intelligent Anti-Tampering Technology	✓	✗	✗	
Locking Paper Tray	✓	Optional	Optional	Print Speed Black, Letter: ISO/Best Quality First Page Out Print Quality, Black Best Duty Cycle, Monthly Monthly Volume Two-Sided Printing Up to 65 ppm As fast as 5.3 Up to 1200 x 1200 dpi Up to 275,000 pages 5,000 - 25,000 pages Manual

M608n Specifications
Print Speed Black, Letter: ISO/Best Quality First Page Out Print Quality, Black Best Duty Cycle, Monthly Monthly Volume Two-Sided Printing Up to 75 ppm As fast as 5.3 sec Up to 1200 x 1200 dpi Up to 300,000 pages 5,000 - 30,000 pages Automatic

M609dn Specifications
Print Speed Black, Letter: ISO/Best Quality First Page Out Print Quality, Black Best Duty Cycle, Monthly Monthly Volume Two-Sided Printing Up to 75 ppm As fast as 5.3 sec Up to 1200 x 1200 dpi Up to 300,000 pages 5,000 - 30,000 pages Automatic

PART NUMBER	PRINTER	TRAYS / PAGES / LOCKS	SHIPPING DIMENSIONS & WEIGHT	
110V	01-06610-101	TROY M607n MICR Printer	1 / 550 / No Lock	20 x 23 x 21in / 54 lbs (24.5 kg)
	01-06610-111	TROY M607n MICR Printer	1 / 550 / 1 Lock	20 x 23 x 21in / 54 lbs (24.5 kg)
	01-06620-101	TROY M608n MICR Secure Printer	1 / 550 / No Lock	20 x 23 x 21in / 54 lbs (24.5 kg)
	01-06620-111	TROY M608n MICR Secure Printer	1 / 550 / 1 Lock	20 x 23 x 21in / 54 lbs (24.5 kg)
	01-06630-111	TROY M608n MICR Secure Ex Printer	1 / 550 / 1 Lock	20 x 23 x 21in / 54 lbs (24.5 kg)
	01-06624-101	TROY M609dn MICR Secure Printer	1 / 550 / No Lock	20 x 23 x 21in / 54 lbs (24.5 kg)
	01-06624-111	TROY M609dn MICR Secure Printer	1 / 550 / 1 Lock	20 x 23 x 21in / 54 lbs (24.5 kg)
	01-06634-111	TROY M609dn MICR Secure Ex Printer	1 / 550 / 1 Lock	20 x 23 x 21in / 54 lbs (24.5 kg)
	220V	01-06610-112	TROY M607n MICR Printer	1 / 550 / 1 Lock
01-06620-112		TROY M608n MICR Secure Printer	1 / 550 / 1 Lock	20 x 23 x 21in / 54 lbs (24.5 kg)
01-06630-112		TROY M608n MICR Secure Ex Printer	1 / 550 / 1 Lock	20 x 23 x 21in / 54 lbs (24.5 kg)

PART NUMBER	ACCESSORY	TRAYS / PAGES / YIELD	SHIPPING DIMENSIONS & WEIGHT
02-03153-001	TROY M607/M608/M609 Secure Locking Tray	550	24 x 22 x 10 / 17 lbs (7.8 kg)
05-00218-001	TROY M607/M608/M609 Standard Tray	550	24 x 22 x 10 / 17 lbs (7.8 kg)
05-00219-001	TROY M607/M608/M609 High Capacity Standard Tray	2,100	23 x 18 x 20 / 29 lbs (13.2 kg)
02-82040-001	TROY M607/M608/M609 MICR Toner Secure STY	Yield 11,000	15 x 8 x 11 / 5 lbs (2.3 kg)
02-82041-001	TROY M608/M609 MICR Toner Secure HY	Yield 25,000	15 x 8 x 11 / 6 lbs (2.7 kg)
02-03160-001	TROY M607/M608/M609 2,100 Secure Sheet Input Tray	1 / 2,100 / 1 Lock	23 x 29 x 20 / 25 lbs (11.4kg)

IN WARRANTY	1 YEAR	3 YEAR	5 YEAR	AFTER WARRANTY	1 YEAR
M607 Same Day Service in warranty	77-10002-607	77-10032-607	77-10052-607	M607 Same Day Service after warranty	77-10004-607
M607 Next Day Service in warranty	77-10001-607	77-10031-607	77-10051-607	M607 Next Day Service after warranty	77-10003-607
M608 Same Day Service in warranty	77-10002-608	77-10032-608	77-10052-608	M608 Same Day Service after warranty	77-10004-608
M608 Next Day Service in warranty	77-10001-608	77-10031-608	77-10051-608	M608 Next Day Service after warranty	77-10003-608
M609 Same Day Service in warranty	77-10002-609	77-10032-609	77-10052-609	M609 Same Day Service after warranty	77-10004-609
M609 Next Day Service in warranty	77-10001-609	77-10031-609	77-10051-609	M609 Next Day Service after warranty	77-10003-609

