



LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

## Ella LED Vanity ELAV Series

### Features

Slim profile modern vanity off set light bars. Ideal use for general lighting in indoor residential, commercial, and hospitality applications. Fixture can be mounted horizontally or vertically to a standard junction box (not included).

### Construction

Fabricated metal housing. Standard mounting holes and hardware are included. Power supply connections must be made inside a junction box (not included).

### Finish

Black, Satin Brass or Satin Nickel finish.

### Diffuser

Frosted white acrylic diffuser.

### Electrical

Input 120 VAC 60 Hz.  
Compatible with residential TRIAC and ELV dimmers.

### LED

Integrated LED modules capable of producing:  
18W = 1400 delivered lumens  
25W = 1800 delivered lumens  
3000K (CCT). Rated for 50,000 Hrs., 90 CRI.



### Certification

All fixtures are cETLus listed for indoor damp locations.  
ADA Compliant  
Title 24/JA8 Compliant

### Warranty

Limited warranty: This fixture is free from defects in materials and workmanship for a period of 5 year from date of purchase.

**Specifications and dimensions**  
subject to change without notice.

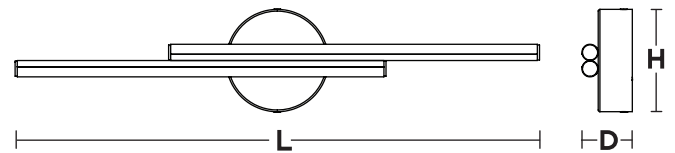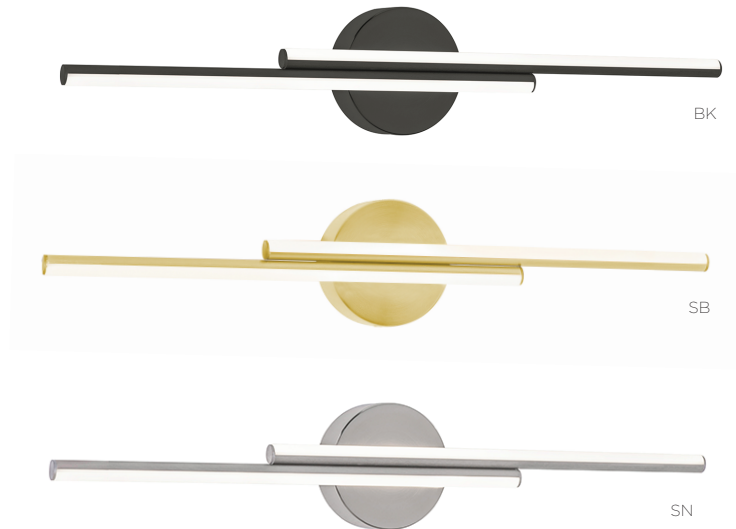

## Ordering Information:

Black	Satin Brass	Satin Nickel	LED	Delivered Lumens	CCT	L	H	D
ELAV2404L30D1BK	ELAV2404L30D1SB	ELAV2404L30D1SN	18W	1400	3000K	24-1/4"	4-3/4"	2-1/4"
ELAV3004L30D1BK	ELAV3004L30D1SB	ELAV3004L30D1SN	25W	1800	3000K	30"	4-3/4"	2-1/4"