



LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

Monroe LED Flush Mount MRF Series



Features

Die-cast metal finial with white acrylic diffuser. Ideal use in kitchens, hallways, and anywhere general lighting is needed. Provides lighting in residential, commercial and hospitality applications. Fixture mounts to standard junction box (not included).

Construction

A 22-gauge steel housing made by stamping process and painted in lighting grade white. A square vacuum formed diffuser is secured with metal square decorative plate and finial in matching finish. Standard mounting holes and hardware included. Power supply connections must be made inside a junction box (not included).

Finish

Satin Nickel metal finial.

Diffuser

0.100" thick vacuum formed smooth white acrylic.

Electrical

Input 120 VAC 60 Hz.

Compatible with residential (TRIAC/ELV) dimmers.

LED

Integrated LED modules capable of producing:
30W = 2400 source lumens, 1540 delivered lumens
Adjustable Choice 3000K, 3500K, 4000K (CCT).
Rated for 50,000 Hrs. 90 CRI.


Certification

All fixtures are cETLus listed for indoor damp locations.

Warranty

Limited warranty: This fixture is free from defects in materials and workmanship for a period of 5 years from date-of-purchase.

**Specifications and dimensions
subject to change without notice.**

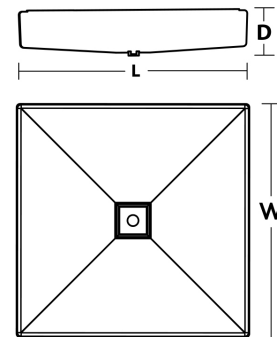

Ordering Information:

Satin Nickel	LED	Source Lumens	Delivered Lumens	Adjustable CCT	L	W	D
MRF1624LAJD1SN	30W	2400	1540	3000K/3500K/4000K	16-1/8"	16-1/8"	3-1/4"