



LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

## LED Closet Light T5LC Series

### Features

All purpose direct wire LED closet light. Low profile for smaller closets. Standard knockouts are located on top, back or ends for direct connection. A direct wire UL listed connector is included and is suitable for 3/8" flexible conduit or 3-wire Romex. Luminaire is suitable for installation within a clothes closet storage space.

### Construction

Housing is die-formed of 22-gauge steel. Separate hinge service tray allows for easy installation and snaps into position without hardware. Power connections are made inside service tray.

### Finish

All exposed metal parts are post painted lighting grade white paint.

### Diffuser

Smooth white acrylic diffuser snap-fits into housing.

### Electrical

This unit is wired for 120V operation. On/off switch rocker or pull chain switch (included).

### Lamping

LED lamping, type SMT array, 4000K non-replaceable, Rated 50,000 hrs., 90 CRI.


### Certification

cETLus listed for damp locations  
ENERGY STAR® qualified  
Title 24/JA8 compliant  
FCC compliant

### Warranty

Limited warranty. This fixture guaranteed to be free from defects in materials and workmanship for a period of 5 years from date of purchase.




**Specifications and dimensions**  
subject to change without notice.

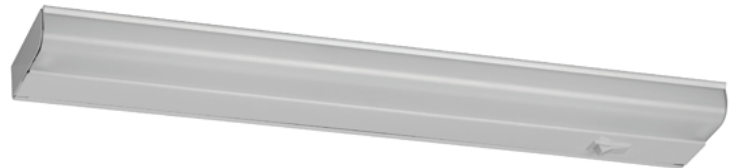

T5LCLT



 T5LCLTP

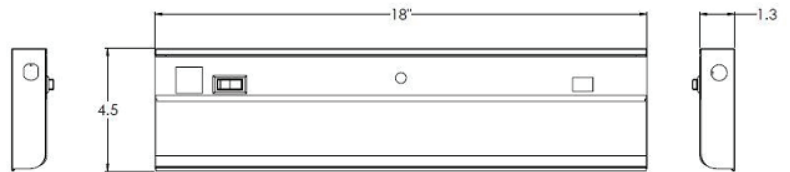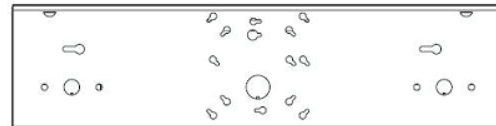

## Ordering Information:

White	Type	Watt	Lumens	LPW	L	W	D
T5LCLT (on/off rocker switch)	SMT-Array	9	700	77	18"	4-1/2"	1-1/8"
T5LCLTP (on/off pull chain switch)	SMT-Array	9	700	77	18"	4-1/2"	1-1/8"