



## LED Industrial Grade Vaportite VTL Series

### Features

Designed for applications requiring an industrial grade fixture that can be used where dirt, dust, humidity, moisture and cold temperatures are present. The white polycarbonate housing is fully gasketed and snap fit polycarbonate latches provide a tight fit between the lens and housing.

### Construction

Impact resistant white polycarbonate housing. Power supply connections can be made inside the fixture wire way or in a junction box (not included).

### Finish

White polycarbonate.

### Diffuser

Clear polycarbonate diffuser.

### Electrical

This unit is wired with a constant current low voltage electronic LED driver. 120-277V universal voltage (non-dimmable) driver.

### Lamping

50,000 hr. long life replaceable LEDs produce 3500 source lumens. 4000K color temperature, 90 CRI.

### Certification


cETLus listed for wet locations.

### Warranty

Limited warranty: This fixture is free from defects in materials and workmanship for a period of 5 years from date of purchase.

Specifications and dimensions subject to change without notice.

LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

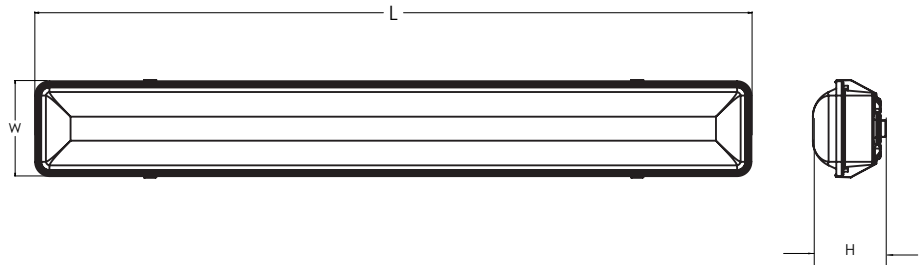

## Ordering Information:

Cool White	LED	Source Lumens	CCT	L	W	H
VTL483500L40MV	34W	3500	4000K	48"	6-3/4"	5-1/8"