

Stock Code: **20086LEDD-BL/CLR**

Collection: Reveal

PRODUCT INFORMATION

Base: 20086 Parent: 20086LEDD
Mounting Type: Portable UPC: 641594231564
Finish: Black
Diffuser: Clear

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length: 7.25"	Length
Width: 7.25"	Width:
Diameter	Diameter:
Height: 11.5"	Height:
Extension:	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Metal	
Diffuser Material: Glass	
Lamping Type: SSL (Dedicated LED)	Jbox: N/A
Lamping Base: SSL	Lamp Wattage: 4 W
Lamp Quantity: 1	Total Wattage: 4 W
Voltage: 120v	Lamps Included: Yes

QUALIFICATIONS

Location Rating: Wet	
Certification: ETL (US/Canada) Listed	
ADA Compliant: No	Energy Star: No
JA8 Compliant: No	Emergency Lighting: No
Marine Grade: No	Warranty: 5 Year

PHOTOMETRICS

Dimmable: Yes	Nominal Lumens: 300 Lm
CRI: 80	Delivered Lumens: N/A
CCT: 3000K	
Recommended Dimmers:	

Additional Notes:

Optional Color Temperature 100 Piece Minimum Order Quantity;
Custom Finish 100 Piece Minimum Order Quantity

Project Name: _____

Location: _____


Type: _____

Quantity: _____

Notes: _____



LINE DRAWING

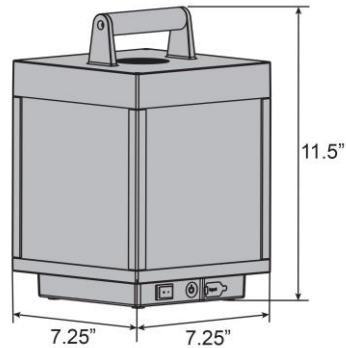

IES FILE

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

