

Stock Code: **20091LEDMG-BRZ/ACR**

Collection: **GEO**

PRODUCT INFORMATION

Base: 20091 Parent: 20091LEDMG
Mounting Type: Wall UPC: 641594244427
Finish: Bronze
Diffuser: Acrylic Lens

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width: 6.5"	Width:
Diameter	Diameter:
Height: 18"	Height:
Extension: 4"	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Steel	
Diffuser Material: Acrylic	
Lamping Type: SSL (Dedicated LED)	Jbox: Standard
Lamping Base: SSL	Lamp Wattage: 20 W
Lamp Quantity: 1	Total Wattage: 20 W
Voltage: 120-277v	Lamps Included: Yes

QUALIFICATIONS

Location Rating: Wet	
Certification: ETL (US/Canada) Listed	
ADA Compliant: Yes	Energy Star: No
JA8 Compliant: Outdoor Only	Emergency Lighting: No
Marine Grade Finish: Yes	
Warranty: 5 Year	

PHOTOMETRICS

Dimmable: Yes	Nominal Lumens: 1800 Lm
CRI: 90	Delivered Lumens: 1395 Lm
CCT: 3000K	
Recommended Dimmers:	
(TRIAC)LUTRON Diva DVCL-153P; (ELV)LUTRON Maestro CL MACL-153M	


ADDITIONAL NOTES

Optional Color Temperature 100 Piece Minimum Order Quantity;
Custom Finish 100 Piece Minimum Order Quantity


Project Name: _____
 Location: _____
 Type: _____
 Quantity: _____
 Notes: _____



LINE DRAWING

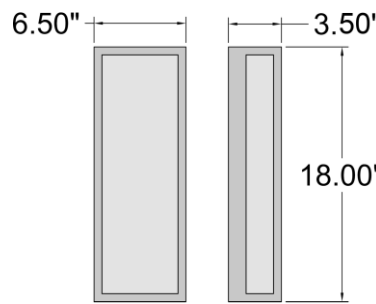

IES FILE

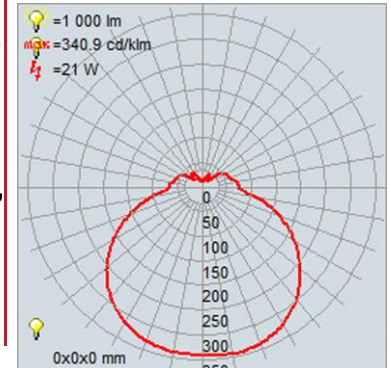

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

