

Stock Code: **20106LEDMG-BRZ/ACR**

Collection: Cove

**PRODUCT INFORMATION**

Base: 20106 Parent: 20106LEDMG  
Mounting Type: Wall UPC: 641594223217  
Finish: Bronze  
Diffuser: Acrylic Lens

Project Name: \_\_\_\_\_

Location: \_\_\_\_\_

Type: \_\_\_\_\_

Quantity: \_\_\_\_\_

Notes: \_\_\_\_\_

**PRODUCT MEASUREMENTS**

<b>FIXTURE</b>	<b>BACKPLATE / CANOPY</b>
Length:	Length
Width: 6.25"	Width: 3.25"
Diameter	Diameter:
Height: 18"	Height: 17.75"
Extension: 4"	
Overall Height:	



**TECHNICAL SPECIFICATIONS**

**SPECIFICATIONS**

Frame Material: Metal	
Diffuser Material: Acrylic	
Lamping Type: SSL (Dedicated LED)	Jbox: Standard
Lamping Base: SSL	Lamp Wattage: 20 W
Lamp Quantity: 1	Total Wattage: 20 W
Voltage: 120-277v	Lamps Included: Yes

**QUALIFICATIONS**

Location Rating	Wet
Certification:	ETL (US/Canada) Listed
ADA Compliant:	Yes
Energy Star:	No
JA8 Compliant:	Outdoor Only
Emergency Lighting:	No
Marine Grade Finish:	Yes
Warranty:	5 Year


**PHOTOMETRICS**

Dimmable: No	Nominal Lumens	1300 Lm
CRI: 90	Delivered Lumens:	1153 Lm
CCT: 3000K		
Recommended Dimmers:		


**ADDITIONAL NOTES**

Optional Color Temperature 100 Piece Minimum Order Quantity;  
Custom Finish 5 Piece Minimum Order Quantity

**LINE DRAWING**

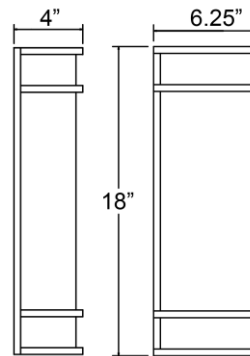

**IES FILE**

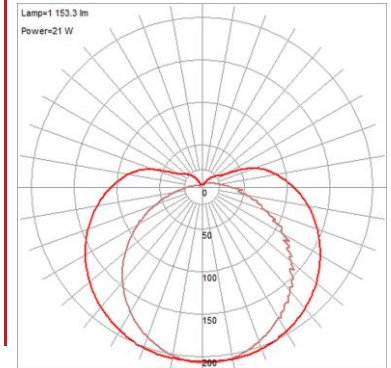

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

**Toll Free 800-828-5483 www.AccessLighting.com**

14410 Myford Road, Irvine, CA 92606

