

Stock Code: **20296LEDDL-PL-BL/FST**

Collection: Nauticus Dual Mount

**PRODUCT INFORMATION**

Base: 20296 Parent: 20296LEDDL-PL  
Mounting Type: Ceiling or Wall UPC: 641594216455  
Finish: Black  
Diffuser: Frosted

**PRODUCT MEASUREMENTS**

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 9.5"	Diameter: 9.5"
Height:	Height: 1"
Extension: 5"	
Overall Height:	

**TECHNICAL SPECIFICATIONS**

**SPECIFICATIONS**

Frame Material: Aluminum  
Diffuser Material: Glass  
Lamping Type: E-26 (Replaceable LED Jbox: Standard  
Lamping Base: E-26 Lamp Wattage: 10 W  
Lamp Quantity: 1 Total Wattage: 10 W  
Voltage: 120v Lamps Included: Yes

**QUALIFICATIONS**

Location Rating Wet  
Certification: UL (US/Canada) Listed  
ADA Compliant: No Energy Star: No  
JA8 Compliant: Yes Emergency Lighting: No  
Marine Grade: No Warranty: 1 Year

**PHOTOMETRICS**

Dimmable: Yes Nominal Lumens 800 Lm  
CRI: 80 Delivered Lumens: N/A  
CCT: 3000K  
Recommended Dimmers:  
(TRIAC)LEVITON Surslide 6631; (TRIAC)LEVITON Decora  
Sureslide 6672; (TRIAC)LEVITON illumatech IPI06;  
(TRIAC)LUTRON Diva DVCL-153P

**Additional Notes:**

Custom Finish 5 Piece Minimum Order Quantity

Project Name: \_\_\_\_\_

Location: \_\_\_\_\_


Type: \_\_\_\_\_

Quantity: \_\_\_\_\_

Notes: \_\_\_\_\_



**LINE DRAWING**

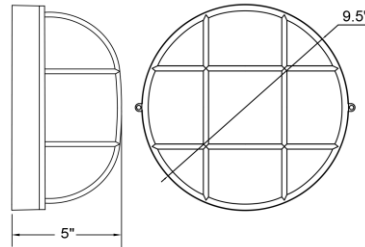

**IES FILE**

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

**Toll Free 800-828-5483 www.AccessLighting.com**

14410 Myford Road, Irvine, CA 92606

