

Stock Code: **20296LEDDL-PP-WH/FST**

Collection: Nauticus Dual Mount

PRODUCT INFORMATION

Base: 20296 Parent: 20296LEDDL-PP
Mounting Type: Ceiling or Wall UPC: 641594216110
Finish: White
Diffuser: Frosted

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 9.5"	Diameter: 9.5"
Height:	Height: 1"
Extension: 5"	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Aluminum
 Diffuser Material: Glass
 Lamping Type: E-26 (Replaceable LED Jbox: Standard
 Lamping Base: E-26 Lamp Wattage: 10 W
 Lamp Quantity: 1 Total Wattage: 10 W
 Voltage: 120v Lamps Included: Yes

QUALIFICATIONS

Location Rating Wet
 Certification: UL (US/Canada) Listed
 ADA Compliant: No Energy Star: No
 JA8 Compliant: Yes Emergency Lighting: No
 Marine Grade: No Warranty: 1 Year

PHOTOMETRICS

Dimmable: Yes Nominal Lumens 800 Lm
 CRI: 80 Delivered Lumens: N/A
 CCT: 3000K
 Recommended Dimmers:
 (TRIAC)LEVITON illumatech IPI06; (TRIAC)LUTRON Diva DVCL-153P;
 (TRIAC)LEVITON Decora Sureslide 6672;
 (TRIAC)LEVITON Surslide 6631


Additional Notes:
Custom Finish 5 Piece Minimum Order Quantity

Project Name: _____
 Location: _____
 Type: _____
 Quantity: _____
 Notes: _____



LINE DRAWING

IES FILE

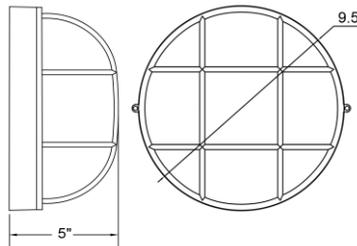

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

