

Stock Code: **20350LEDDMGLP-BRZ/CLR**

Collection: KO

PRODUCT INFORMATION

Base: 20350 Parent: 20350LEDDMGL
Mounting Type: Wall UPC: 641594200645
Finish: Bronze
Diffuser: Clear

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width: 4.25"	Width:
Diameter	Diameter:
Height: 4.25"	Height: 1.5"
Extension: 4"	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Aluminum
Diffuser Material: Glass
Lamping Type: GU-10 (Replaceable LE Jbox: Standard
Lamping Base: GU-10 Lamp Wattage: 5.3 W
Lamp Quantity: 1 Total Wattage: 5.3 W
Voltage: 120v Lamps Included: Yes

QUALIFICATIONS

Location Rating Wet
Certification: UL (US/Canada) Listed
ADA Compliant: Yes Energy Star: No
JA8 Compliant: No Emergency Lighting: No
Marine Grade Finish: Yes
Warranty: 5 Year

PHOTOMETRICS

Dimmable: Yes Nominal Lumens 346 Lm
CRI: 80 Delivered Lumens: N/A
CCT: 3000K
Recommended Dimmers:
(TRIAC)LEVITON Trimatron 6684; (TRIAC)LEVITON Surslide 6631; (TRIAC)LUTRON Diva DVCL-153P; (TRIAC)LUTRON Skylark S-600 or S-600P; (TRIAC)LUTRON Diva DV-600P

ADDITIONAL NOTES

Can be Mounted Bulb Up or Bulb Down; Custom Finish 100 Piece Minimum Order Quantity

Project Name: _____

Location: _____


Type: _____

Quantity: _____

Notes: _____



LINE DRAWING

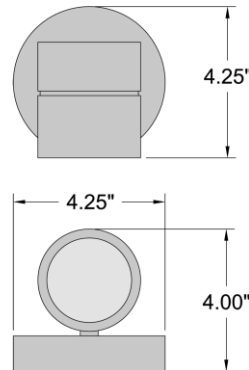

IES FILE

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

The information is subject to change without notice. 12/22/2022 20350LEDDMGLP-BRZ_CLR.pdf

