

Stock Code: **20415LED-ALB**

Collection: Daphne

PRODUCT INFORMATION

Base: 20415 Parent: 20415LED
Mounting Type: Wall UPC: 641594187908
Finish: Brushed Steel
Diffuser: Alabaster

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length 8.5"
Width: 5.5"	Width: 4.25"
Diameter	Diameter:
Height: 11.75"	Height: 0.5"
Extension: 4"	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Steel
Diffuser Material: Glass
Lamping Type: SSL (Dedicated LED) Jbox: Standard
Lamping Base: SSL Lamp Wattage: 10.8 W
Lamp Quantity: 1 Total Wattage: 10.8 W
Voltage: 120v Lamps Included: Yes

QUALIFICATIONS

Location Rating Damp
Certification: UL (US/Canada) Listed
ADA Compliant: Yes Energy Star: Yes
JA8 Compliant: No Emergency Lighting: No
Marine Grade: No Warranty: 5 Year

PHOTOMETRICS

Dimmable: Yes Nominal Lumens 1265 Lm
CRI: 90 Delivered Lumens: N/A
CCT: 3000K
Recommended Dimmers:
(TRIAC)LEVITON Surslide 6631; (MLV)LUTRON Diva DVLV-600P; (TRIAC)LUTRON Diva DVCL-153P; (ELV)LEVITON Illumatech IPE04; (ELV)LUTRON Maestro MAELV-600; (ELV)LUTRON Diva DVELV-300P

Additional Notes:

Project Name: _____

Location: _____


Type: _____

Quantity: _____

Notes: _____



LINE DRAWING

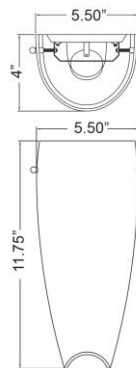

IES FILE

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

The information is subject to change without notice. 12/15/2022 20415LED-ALB.pdf

