

Stock Code: **20444LEDDL-PRZ**

Collection: Uptown

PRODUCT INFORMATION

Base: 20444 Parent: 20444LEDDL-PRZ
Mounting Type: Wall UPC: 641594229592
Finish: Bronze
Diffuser: N/A

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width: 4.75"	Width:
Diameter	Diameter:
Height: 12"	Height: 0.5"
Extension: 7"	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Steel
 Diffuser Material: N/A
 Lamping Type: E-26 (Replaceable LED Jbox: Standard
 Lamping Base: E-26 Lamp Wattage: 10 W
 Lamp Quantity: 2 Total Wattage: 20 W
 Voltage: 120v Lamps Included: Yes

QUALIFICATIONS

Location Rating Damp
 Certification: UL (US/Canada) Listed
 ADA Compliant: No Energy Star: No
 JA8 Compliant: Yes Emergency Lighting: No
 Marine Grade: No Warranty: 1 Year

PHOTOMETRICS

Dimmable: Yes Nominal Lumens 1600 Lm
 CRI: 90 Delivered Lumens: N/A
 CCT: 3000K
 Recommended Dimmers:
 (ELV)LUTRON Skylark SELV-300P; (MLV)COOPER Aspire
 9530SW; (TRIAC)LEGRAND Titan CD703-PW

Additional Notes:

Bi-Directional Light Source; Custom Finish 5 Piece Minimum Order Quantity

Project Name: _____

Location: _____


Type: _____

Quantity: _____

Notes: _____



LINE DRAWING

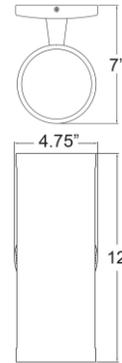

IES FILE

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

