

Stock Code: **20625LEDD-BS/OPL**

Collection: Cobalt

PRODUCT INFORMATION

Base: 20625 Parent: 20625LEDD
Mounting Type: Ceiling UPC: 641594200379
Finish: Brushed Steel
Diffuser: Opal

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 13"	Diameter: 13"
Height: 4"	Height: 1.5"
Extension:	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Steel
Diffuser Material: Glass
Lamping Type: SSL (Dedicated LED) Jbox: Standard
Lamping Base: SSL Lamp Wattage: 17 W
Lamp Quantity: 1 Total Wattage: 17 W
Voltage: 120v Lamps Included: Yes

QUALIFICATIONS

Location Rating Damp
Certification: UL (US/Canada) Listed
ADA Compliant: No Energy Star: Yes
JA8 Compliant: No Emergency Lighting: No
Marine Grade: No Warranty: 5 Year

PHOTOMETRICS

Dimmable: Yes Nominal Lumens 1440 Lm
CRI: 90 Delivered Lumens: 592 Lm
CCT: 3000K
Recommended Dimmers:
(ELV)LUTRON Diva DVELV-300P; (ELV)LEGRAND Paddle
ADPD453LM2; (TRIAC)LUTRON Diva DVCL-153P;
(ELV)LUTRON Diva DVELV-303P; (ELV)LUTRON Skylark SELV-
300P

Additional Notes:

Optional Color Temperature 5 Piece Minimum Order Quantity; Custom
Finish 5 Piece Minimum Order Quantity

Project Name: _____

Location: _____


Type: _____

Quantity: _____


Notes: _____



LINE DRAWING

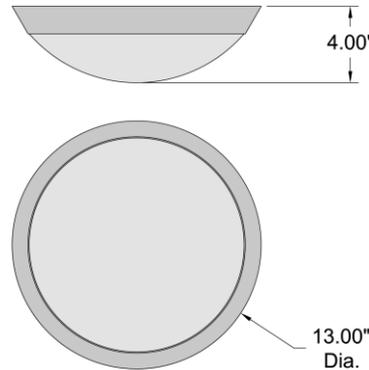

IES FILE

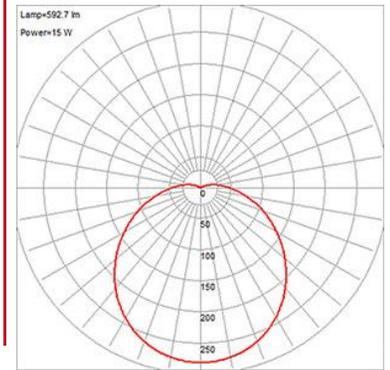

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

