

Stock Code: **20671LEDD-CH/OPL**

Collection: Aero

### PRODUCT INFORMATION

Base: 20671 Parent: 20671LEDD  
Mounting Type: Ceiling UPC: 641594199963  
Finish: Chrome  
Diffuser: Opal

### PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 12.5"	Diameter:
Height: 4"	Height: 1"
Extension:	
Overall Height:	

### TECHNICAL SPECIFICATIONS

#### SPECIFICATIONS

Frame Material: Steel  
Diffuser Material: Glass  
Lamping Type: SSL (Dedicated LED) Jbox: Standard  
Lamping Base: SSL Lamp Wattage: 17 W  
Lamp Quantity: 1 Total Wattage: 17 W  
Voltage: 120v Lamps Included: Yes

#### QUALIFICATIONS

Location Rating Damp  
Certification: UL (US/Canada) Listed  
ADA Compliant: No Energy Star: Yes  
JA8 Compliant: No Emergency Lighting: No  
Marine Grade: No Warranty: 5 Year

#### PHOTOMETRICS

Dimmable: Yes Nominal Lumens 1440 Lm  
CRI: 90 Delivered Lumens: 1002 Lm  
CCT: 3000K  
Recommended Dimmers:  
(TRIAC)LUTRON Diva DV-600P; (ELV)LUTRON Skylark SELV-300P; (ELV)LEGRAND Paddle ADPD453LM2; (ELV)LUTRON Diva DVELV-300P; (ELV)LUTRON Diva DVELV-303P

#### Additional Notes:

Custom Finish 100 Piece Minimum Order Quantity

Project Name: \_\_\_\_\_

Location: \_\_\_\_\_


Type: \_\_\_\_\_

Quantity: \_\_\_\_\_


Notes: \_\_\_\_\_



#### LINE DRAWING

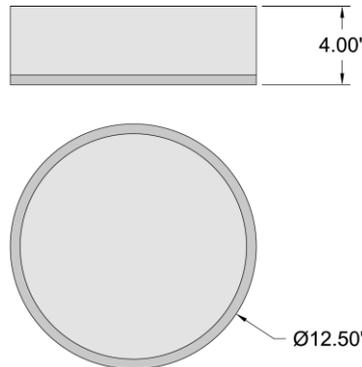

#### IES FILE

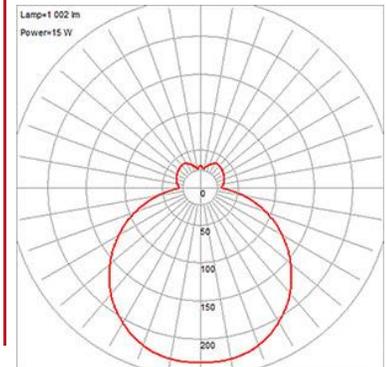

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

Toll Free 800-828-5483 [www.AccessLighting.com](http://www.AccessLighting.com)

14410 Myford Road, Irvine, CA 92606

