

Stock Code: **20832LEDD-CH/ACR**

Collection: ModPLUS

**PRODUCT INFORMATION**

Base: 20832 Parent: 20832LEDD  
Mounting Type: Ceiling UPC: 641594231595  
Finish: Chrome  
Diffuser: Acrylic Lens

**PRODUCT MEASUREMENTS**

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 12"	Diameter:
Height: 0.5"	Height:
Extension:	
Overall Height:	

**TECHNICAL SPECIFICATIONS**

**SPECIFICATIONS**

Frame Material: Acrylic  
Diffuser Material: Acrylic  
Lamping Type: SSL (Dedicated LED) Jbox: Pancake  
Lamping Base: SSL Lamp Wattage: 24 W  
Lamp Quantity: 1 Total Wattage: 24 W  
Voltage: 120v Lamps Included: Yes

**QUALIFICATIONS**

Location Rating Damp  
Certification: ETL (US/Canada) Listed  
ADA Compliant No Energy Star: No  
JA8 Compliant: Yes Emergency Lighting: No  
Marine Grade: No Warranty: 5 Year

**PHOTOMETRICS**


Dimmable: Yes Nominal Lumens 1920 Lm  
CRI: 90 Delivered Lumens: 1532 Lm  
CCT: 3000K  
Recommended Dimmers:  
(TRIAC)LUTRON Diva DVCL-153P; (ELV)LUTRON Caseta PD -  
6WCL; (ELV)LUTRON Maestro MRF2-6CL; (ELV)LUTRON  
Maestro CL MACL-153M

Additional Notes:


Project Name: \_\_\_\_\_  
Location: \_\_\_\_\_  
Type: \_\_\_\_\_  
Quantity: \_\_\_\_\_  
Notes: \_\_\_\_\_



**LINE DRAWING**

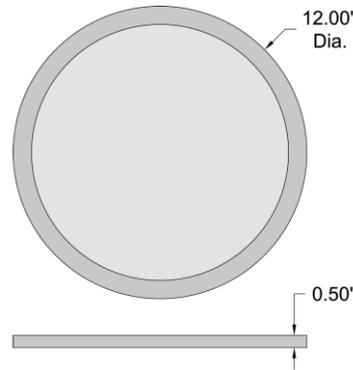

**IES FILE**

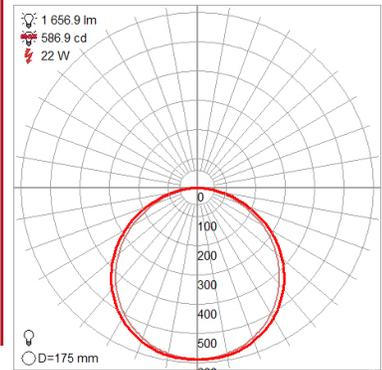

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

**Toll Free 800-828-5483 www.AccessLighting.com**

14410 Myford Road, Irvine, CA 92606

