

Stock Code: **20836LEDD-BL/ACR**

Collection: ModPLUS

### PRODUCT INFORMATION

Base: 20836 Parent: 20836LEDD  
Mounting Type: Ceiling UPC: 641594236026  
Finish: Brushed Steel  
Diffuser: Acrylic Lens

### PRODUCT MEASUREMENTS

| FIXTURE         | BACKPLATE / CANOPY |
|-----------------|--------------------|
| Length:         | Length             |
| Width:          | Width:             |
| Diameter 7"     | Diameter:          |
| Height: 0.5"    | Height:            |
| Extension:      |                    |
| Overall Height: |                    |

### TECHNICAL SPECIFICATIONS

#### SPECIFICATIONS

Frame Material: Acrylic  
Diffuser Material: Acrylic  
Lamping Type: SSL (Dedicated LED) Jbox: Standard  
Lamping Base: SSL Lamp Wattage: 12 W  
Lamp Quantity: 1 Total Wattage: 12 W  
Voltage: 120-277v Lamps Included: Yes

#### QUALIFICATIONS

Location Rating Damp  
Certification: ETL (US/Canada) Listed  
ADA Compliant No Energy Star: No  
JA8 Compliant: No Emergency Lighting: No  
Marine Grade: No Warranty: 5 Year

#### PHOTOMETRICS

Dimmable: Yes Nominal Lumens 1400 Lm  
CRI: 80 Delivered Lumens: 871 Lm  
CCT: 3000K  
Recommended Dimmers:  
(0-10V)LUTRON NFTV-WH; (0-10V)LUTRON DVSTV-WH; (0-10V)LEVITON DS710-102; (0-10V)LEVITON DD710-BLZ

#### Additional Notes:

0-10V Source Dimming

Project Name: \_\_\_\_\_

Location: \_\_\_\_\_


Type: \_\_\_\_\_

Quantity: \_\_\_\_\_

Notes: \_\_\_\_\_



#### LINE DRAWING

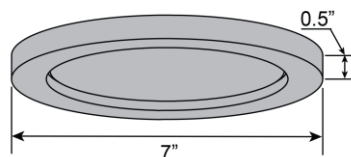

#### IES FILE

