

Stock Code: **20840LEDD-BL/ACR**

Collection: ModPLUS

PRODUCT INFORMATION

Base: 20840 Parent: 20840LEDD
Mounting Type: Ceiling UPC: 641594236057
Finish: Black
Diffuser: Acrylic Lens

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length: 8.5"	Length
Width: 8.5"	Width:
Diameter	Diameter:
Height: 0.5"	Height:
Extension:	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Acrylic
Diffuser Material: Acrylic
Lamping Type: SSL (Dedicated LED) Jbox: Standard
Lamping Base: SSL Lamp Wattage: 18 W
Lamp Quantity: 1 Total Wattage: 18 W
Voltage: 120-277v Lamps Included: Yes

QUALIFICATIONS

Location Rating Damp
Certification: ETL (US/Canada) Listed
ADA Compliant No Energy Star: No
JA8 Compliant: No Emergency Lighting: No
Marine Grade: No Warranty: 5 Year

PHOTOMETRICS


Dimmable: Yes Nominal Lumens 1800 Lm
CRI: 80 Delivered Lumens: 1463 Lm
CCT: 3000K
Recommended Dimmers:
(0-10V)LEVITON DS710-102; (0-10V)LEVITON DD710-BLZ; (0-10V)LUTRON DVSTV-WH; (0-10V)LUTRON NFTV-WH

Additional Notes:
0-10V Source Dimming


Project Name: _____
Location: _____
Type: _____
Quantity: _____
Notes: _____



LINE DRAWING

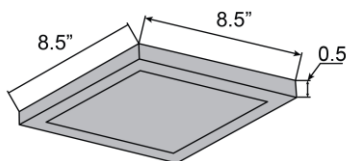

IES FILE

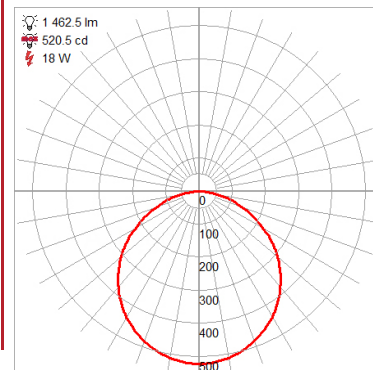

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

The information is subject to change without notice. 9/23/2022 20840LEDD-BL_ACR.pdf

