

Stock Code: **20848LEDD-WH/ACR**

Collection: ModPLUS

PRODUCT INFORMATION

Base: 20848 Parent: 20848LEDD
Mounting Type: Ceiling UPC: 641594231229
Finish: White
Diffuser: Acrylic Lens

PRODUCT MEASUREMENTS

| FIXTURE | BACKPLATE / CANOPY |
|-----------------|--------------------|
| Length: | Length |
| Width: | Width: |
| Diameter 16" | Diameter: |
| Height: 1" | Height: |
| Extension: | |
| Overall Height: | |

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Acrylic
Diffuser Material: Acrylic
Lamping Type: SSL (Dedicated LED) Jbox: Pancake
Lamping Base: SSL Lamp Wattage: 30 W
Lamp Quantity: 1 Total Wattage: 30 W
Voltage: 120v Lamps Included: Yes

QUALIFICATIONS

Location Rating Damp
Certification: ETL (US/Canada) Listed
ADA Compliant No Energy Star: No
JA8 Compliant: Yes Emergency Lighting: No
Marine Grade: No Warranty: 5 Year

PHOTOMETRICS

Dimmable: Yes Nominal Lumens 3300 Lm
CRI: 90 Delivered Lumens: 2214 Lm
CCT: 3000K
Recommended Dimmers:
(ELV)LUTRON Maestro CL MACL-153M; (TRIAC)LEVITON
Decora Sureslide 6672; (TRIAC)LEVITON Decora Sureslide
6674; (TRIAC)LUTRON Skylark CL SCL-153 or SCL-153P;
(TRIAC)LUTRON Diva DVCL-153P

Additional Notes:

Project Name: _____

Location: _____


Type: _____

Quantity: _____

Notes:



LINE DRAWING

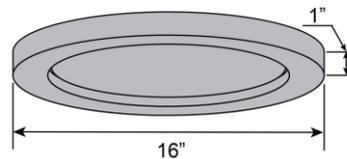

IES FILE

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

